

SmartKeeper USB Type A Blockout Device

specifications

Panduit SmartKeeper USB Type A Blockout Device shall be compatible with USB Type A ports. The device shall be utilized in connections or equipment that use USB Type A adapters and shall mount in place with a simple push blocking access to the USB port to prevent access to sensitive data and to reduce the potential spread of malware through USB enabled devices. The USB Type A Blockout Device shall only unlock with the use of the SmartKeeper Master Key.



SmartKeeper USB Type A Blockout Device, 5/pkg

Red: SKUSBA-V

SmartKeeper Master Key

SKMKEY

technical information

RoHS compliant:	Yes
Temperature range:	-4°F (-20°C) to + 140°F (+60°C)
Material:	Polycarbonate and Brass Steel/Nickel Plated
Packaging:	Five units per package

key features and benefits

Tamper Resistant	Device will block connections from unauthorized access, protecting sensitive data and reducing the risk of transferring malware
Ease of use	Installs with a single push
Compact design	Mounts flush with the opening and does not interfere with adjoining connections
Compatibility	Compliant with USB Type A ports
Master Key	Unique locking mechanism can only be accessed with a special master key




applications

USB Type A ports have become a convenient way to charge and operate multiple devices. It is also an easy way to transfer malware into a network to access or steal sensitive data. Panduit SmartKeeper USB Type A Blockout Device will block most USB Type A ports and can only be removed by using SmartKeeper Master Key.

This tamper resistant device provides an economical way to add a physical layer to secure USB Type A ports found in computers, switches or any other equipment, preventing unauthorized access and reducing the risk of intentional or unintentional damage to help save time and money associated with data security breaches, network downtime, infrastructure repair and hardware replacement.

SmartKeeper USB Type A Blockout Device

dimensions

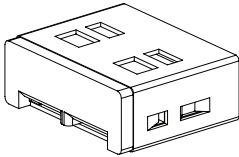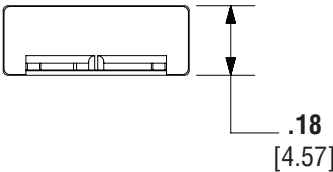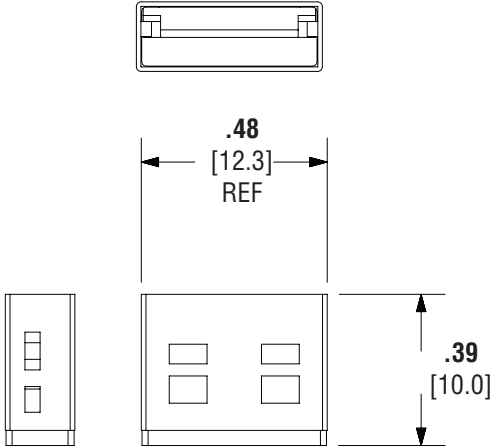

Dimensions are in inches. [Dimensions in brackets are metric].

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com

Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300



© 2019 Panduit Corp.
ALL RIGHTS RESERVED.
Printed in the U.S.A.
SFSP11--WW-ENG
6/2019