


94 series flanged comms boxes

TAKACHI

Product overview

Flanged low profile and deep profile plastic housings with removable end panels. Ideal for surface mounted communication equipment such as Wi-Fi routers.

- Stylishly designed ABS plastic case with double detachable panels
- Flanged sides for surface or wall mounting
- Flame resistant ABS (UL94-V0), 24 sizes, available in off-white
- Equipped with built-in bosses for PCB mounting
- Suitable for WiFi access points, measuring equipment, control and communication applications
- 94 series has been designed to meet the requirements of IP40

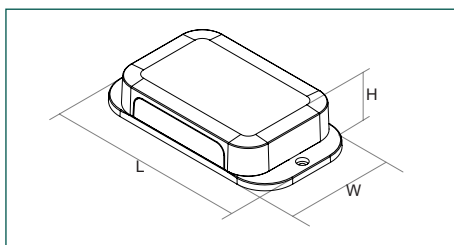

SPECIFICATION	
Materials	ABS UL94-V0
Protection class	94 series has been designed to meet the requirements of IP40
Operating temperature	-10°C to +60°C
Standard colours	Off-white
Standard unit includes	Top cover, flanged base x2 panels x4 self tapping screws

PART NO.	LENGTH	WIDTH	HEIGHT
CDE9401WH	67.3mm	124.3mm	22.5mm
CDE9402WH	100.3mm	124.3mm	22.5mm
CDE9403WH	67.3mm	124.3mm	35mm
CDE9404WH	100.3mm	124.3mm	35mm
CDE9405WH	85.3mm	149.3mm	25mm
CDE9406WH	125.3mm	155.3mm	25mm
CDE9407WH	85.3mm	149.3mm	40mm
CDE9408WH	125.3mm	155.3mm	40mm
CDE9409WH	100.4mm	180.4mm	30mm
CDE9410WH	150.4mm	180.4mm	30mm
CDE9411WH	100.4mm	180.4mm	45mm
CDE9412WH	150.4mm	205.4mm	45mm
CDE9413WH	120.4mm	205.4mm	35mm
CDE9414WH	175.4mm	205.4mm	35mm
CDE9415WH	120.4mm	205.4mm	50mm
CDE9416WH	175.4mm	205.4mm	50mm
CDE9417WH	135.5mm	230.5mm	40mm
CDE9418WH	200.5mm	230.5mm	40mm
CDE9419WH	135.5mm	230.5mm	60mm
CDE9420WH	200.5mm	230.5mm	60mm
CDE9421WH	165.5mm	270.5mm	42.5mm
CDE9422WH	240.5mm	270.5mm	42.5mm
CDE9423WH	165.5mm	270.5mm	60mm
CDE9424WH	240.5mm	270.5mm	60mm

268
HANDHELD CASES

292
UNIVERSAL ENCLOSURES

318
HEAVY DUTY AND ELECTRICAL ENCLOSURES

342
DESKTOP AND INSTRUMENT CASES

348
DEVELOPMENT BOARD ENCLOSURES

367
ROOM SENSOR ENCLOSURES

370
CUSTOM SIZED ENCLOSURES

PLASTIC ENCLOSURES

311

PART NO.	LENGTH	WIDTH	HEIGHT	
CDE9425WH	200.5mm	310.5mm	45mm	NEW
CDE9426WH	200.5mm	310.5mm	65mm	NEW
CDE9427WH	200.5mm	310.5mm	90mm	NEW
CDE9428WH	225.5mm	350.5mm	45mm	NEW
CDE9429WH	225.5mm	350.5mm	70mm	NEW
CDE9430WH	225.5mm	350.5mm	100mm	NEW

KEY FEATURES

Flame resistant ABS | 24 sizes available | Flanged for wall mounting

