

10.3x38mm gPV solar photovoltaic power fuses



Product overview

- Fast gPV type for the protection of photovoltaic modules and their conductors
- Current limiting, super fast blow
- To IEC 60269
- 1000V rated
- UL and TUV approvals

PART NO.	RATING
CFI010gPV/1	1A
CFI010gPV/2	2A
CFI010gPV/3	3A
CFI010gPV/4	4A
CFI010gPV/5	5A
CFI010gPV/6	6A
CFI010gPV/8	8A
CFI010gPV/10	10A
CFI010gPV/12	12A
CFI010gPV/15	15A
CFI010gPV/20	20A



SPECIFICATION		
Rating	CFI0gPV	1000V 1-20A
Breaking capacity	CFI0gPV	2kA @ 1000VDC
Blow time @ I _w = 113% of IR 1 hour min		

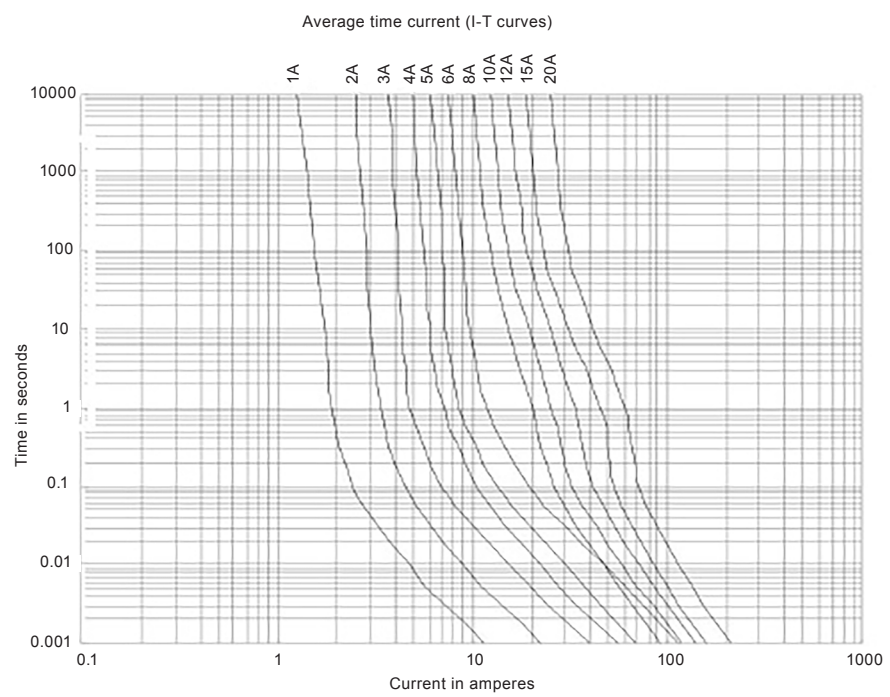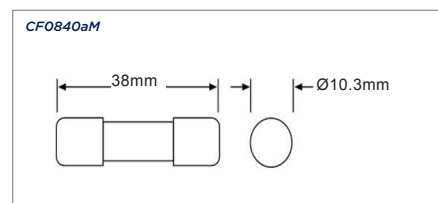

KEY FEATURES

Solar fuses for photovoltaic application | Super fast blow | Current limiting

PROTECT