


# 91 series IP67 low profile cases

## Product overview

Beautifully designed low profile IP67 waterproof enclosures, ideal for tracking/monitoring in harsh environment

- IP67 rated, perfect for outdoor application
- White enclosures made from ASA UL94-HB plastic for high ultraviolet resistance
- Dark grey enclosures made from ABS UL94-V0 plastic for high flammability rating
- Wall mount holes behind hinged caps for superior aesthetic finish
- Mounting kit accessory for easy mounting to poles, pillars, posts and lamp posts
- 91 series has been designed to meet the requirements of IP67

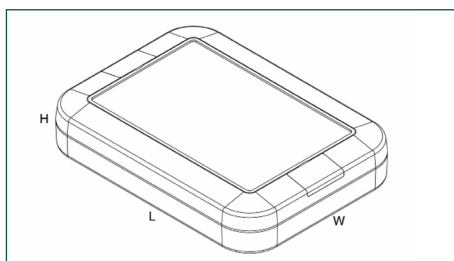

SPECIFICATION	
Material:	Dark grey White grey
	Base and lid ABS UL94-V0 Base and lid ASA UL94-HB
Operating temperature	ABS, -10°C to +50°C ASA, -30°C to +60°C
Standard colours	Dark grey or white grey
Standard unit includes	Lid and base, gasket and fixing screws
Protection class	91 series has been designed to meet the requirements of IP67

DARK GREY		WHITE GREY		LENGTH	WIDTH	HEIGHT
CHD91E7DG	CHD91E7WG	65mm	52mm	18mm		
CHD91E8DG	CHD91E8WG	65mm	52mm	27mm		
CHD91E11DG	CHD91E11WG	75mm	75mm	22mm		
CHD91E12DG	CHD91E12WG	75mm	75mm	35mm		
CHD91E9DG	CHD91E9WG	80mm	60mm	20mm		
CHD91E10DG	CHD91E10WG	80mm	60mm	30mm		
CHD91E13DG	CHD91E13WG	100mm	75mm	22mm		
CHD91E14DG	CHD91E14WG	100mm	75mm	35mm		
CHD91E3DG	CHD91E3WG	100mm	100mm	25mm		
CHD91E4DG	CHD91E4WG	100mm	100mm	40mm		
CHD91E1DG	CHD91E1WG	130mm	90mm	25mm		
CHD91E2DG	CHD91E2WG	130mm	90mm	40mm		
CHD91E5DG	CHD91E5WG	150mm	110mm	27mm		
CHD91E6DG	CHD91E6WG	150mm	110mm	40mm		
CHD91E16DG	CHD91E16WG	175mm	130mm	45mm		
CHD91E15DG	CHD91E15WG	175mm	135mm	30mm		

## KEY FEATURES

IP67 rated | Pole mounting kit accessory | Wall mount holes



**268**  
HANDHELD CASES

**292**  
UNIVERSAL  
ENCLOSURES

**318**  
HEAVY DUTY  
AND ELECTRICAL  
ENCLOSURES

**342**  
DESKTOP AND  
INSTRUMENT  
CASES

**348**  
DEVELOPMENT  
BOARD  
ENCLOSURES

**367**  
ROOM SENSOR  
ENCLOSURES

**370**  
CUSTOM SIZED  
ENCLOSURES

**PLASTIC ENCLOSURES**

**340**

## ACCESSORIES

Rubber feet



PART NO.	LENGTH	WIDTH	HEIGHT
CHD91FEET	10mm	10mm	7.5mm

Pole mount kit



PART NO.	LENGTH	WIDTH	HEIGHT	DESCRIPTION
CHD91PLDG	18mm	14mm	9.5mm	Pole mount kit, dark grey
CHD91PLWG	18mm	14mm	9.5mm	Pole mount kit, white grey
CHD91PMDG	28mm	18mm	12mm	Pole mount kit, dark grey
CHD91PMWG	28mm	18mm	12mm	Pole mount kit, white grey

DARK GREY	WHITE GREY	CHD91PLDG	CHD91PLWG	CHD91PMDG	CHD91PMWG
CHD91E7DG	CHD91E7WG	•	•		
CHD91E8DG	CHD91E8WG	•	•		
CHD91E11DG	CHD91E11WG	•	•		
CHD91E12DG	CHD91E12WG	•	•		
CHD91E9DG	CHD91E9WG	•	•		
CHD91E10DG	CHD91E10WG	•	•		
CHD91E13DG	CHD91E13WG	•	•		
CHD91E14DG	CHD91E14WG	•	•		
CHD91E3DG	CHD91E3WG			•	•
CHD91E4DG	CHD91E4WG			•	•
CHD91E1DG	CHD91E1WG			•	•
CHD91E2DG	CHD91E2WG			•	•
CHD91E5DG	CHD91E5WG			•	•
CHD91E6DG	CHD91E6WG			•	•
CHD91E16DG	CHD91E16WG			•	•
CHD91E15DG	CHD91E15WG			•	•