


THB.402.D1F

TeeTube 5 Pole Screw - end barrier contact 7mm to 13.5mm on one gland 8mm to 17mm on the other gland, 4 mm max conductor size IP68 32A 450V 3 cable entries

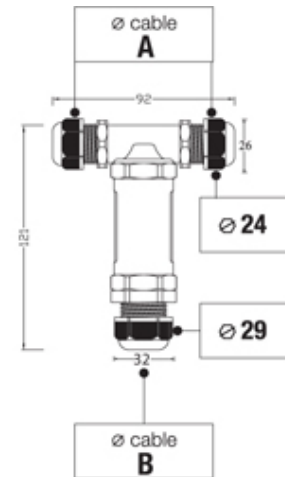

SPECIFICATION

Cable Entries	3
Number of Poles	5
Terminal Type	Screw - end barrier contact
Body Material	PA66 / TPE
IP Rating	68
Max Conductor Size (Sq mm)	4
Max Current (A)	32
Max Voltage (V)	450
Minimum Temp Rating °C	-40
Maximum Temp Rating °C	125
Minimum Cable Diameter (mm)	7
Maximum Cable Diameter (mm)	13.5
Secondary Minimum Cable Diameter (mm)	8
Secondary Maximum Cable Diameter (mm)	17
Fixing System	Cable
Temperature "T" Rating	T85