

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2078450006](#)  
**Status:** **Active**  
**Overview:** [L1NK Connector System](#)  
**Description:** L1NK 250 Terminal Position Assurance (TPA) Retainer, 2.50mm Pitch, 6 Circuits, Natural

**Documents:**

|   |   |
|---|---|
| <a href="#">3D Model</a>  | <a href="#">Packaging Specification 2078450000-PK-000 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>                                     | <a href="#">Test Summary 2079020000-TS-000 (PDF)</a>            |
| <a href="#">3D Model (PDF)</a>                                    | <a href="#">Datasheet (PDF)</a>                                 |
| <a href="#">Product Specification 2079020001-PS-000 (PDF)</a>     | <a href="#">RoHS Certificate of Compliance (PDF)</a>            |
| <a href="#">Application Specification 2079020001-AS-000 (PDF)</a> |   |

**Agency Certification**

CSA 152514

**General**

|                    |                                       |
|--------------------|---------------------------------------|
| Product Family     | Accessories                           |
| Series             | <a href="#">207845</a>                |
| Component Type     | Terminal Position Assurance           |
| Datasheet Order No | 987651-9951                           |
| Overview           | <a href="#">L1NK Connector System</a> |
| Product Name       | L1NK 250                              |
| UPC                | 191130124046                          |


**Physical**

|                               |                |
|-------------------------------|----------------|
| Circuits (Loaded)             | 6              |
| Circuits (maximum)            | 6              |
| Color - Resin                 | Natural        |
| Flammability                  | 94V-0          |
| Lock to Mating Part           | Yes            |
| Material - Resin              | Nylon          |
| Net Weight                    | 0.097/g        |
| Number of Rows                | 1              |
| Packaging Type                | Bag            |
| Temperature Range - Operating | -40° to +105°C |

**Material Info**

**Reference - Drawing Numbers**

|                           |                   |
|---------------------------|-------------------|
| Application Specification | 2079020001-AS-000 |
| Packaging Specification   | 2078450000-PK-000 |
| Product Specification     | 2079020001-PS-000 |
| Sales Drawing             | 2078450004-SD-000 |
| Test Summary              | 2079020000-TS-000 |

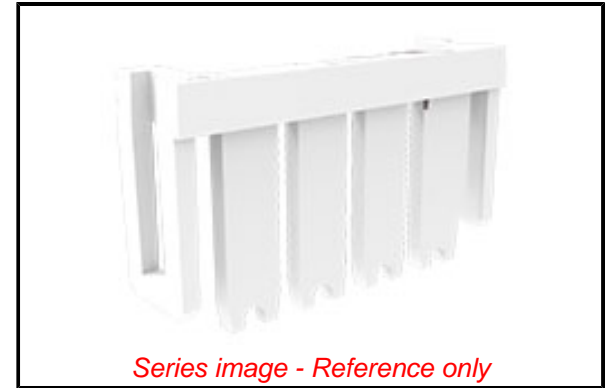

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/71/2019 (16 July 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[207845 Series](#)

**Use With**

L1NK 250 Receptacle Housing [2078410006](#)