

Ratchet P-Clamp, B-Series : RCB180SM6SS

For bundle diameters from 12.7 mm to 19.5 mm, Article number:
151-02736

[Add to watchlist](#)[Images \(17\)](#)

Introducing the Ratchet P-...



P-clamp for a more versati...



Features

- Ratchet P-Clamp B-Series for bundle diameters from 13.2 mm to 19.5 mm
- One-piece ratchet closure design allows for easy installation during pre- or final assembly
- Multiple configurations handle a wide range of diameters and applications, reducing part inventory
- Clamp interior is designed to guide and center bundle to reduce pinching
- Easy release feature allows for quick adjustments and maintenance
- Impact modified, heat and UV stabilized PA66 provides long-term durability, in- and outdoors
- Steel mounting plate tolerates high torque mounting and is treated to resist chemicals and salt spray

Certifications & Approvals



Application

The Ratchet P-Clamp family offers versatility when managing wires, cables and hoses. The robust design and durable materials make it ideal for heavy duty applications, both in- and outdoors. The one-piece adjustable clamp can be closed by hand to the desired diameter. The release feature provides easy and nondestructive removal of cables simply by using a flat-head screwdriver. This nondestructive release allows the clamp to be reused without removing or replacing any bolts or screws. The Ratchet P-Clamp is offered in four sizes and multiple mounting configurations.

For bundle diameters from 12.7 mm to 19.5 mm is suitable for following markets and industries



More products in this product group

Ratchet P-Clamp, B-Series >


Base Data

Colour	Black (BK)
Fixation Method	Screw Mounting
Pack Cont.	280 Bag

Contact

Package Quantity per	bag
PART DESCRIPTION	RCB180SM6SS-PA666V0/SS304-BK
Product Family	For bundle diameters from 12.7 mm to 19.5 mm
Product Group	Ratchet P-Clamp, B-Series
Variant	Short

Product Dimensions

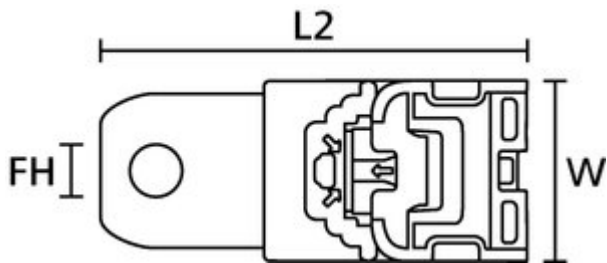

Angle	180 °
Bundle ø max.	19.5 mm
Bundle ø min.	12.7 mm
Fixing Hole Centres (F)	2.08 "
Fixing Hole Centres (F)	52.8 mm
for Hole ø (FH)	6.6 mm
Length (L)	116.2 mm
Length (L2)	83.1 mm
Min.Tensile Strength	445.0 N
Stud ø	M6
Width (W)	34.9 mm
Width (W2)	30.0 mm

Material and Specifications



ELV compliant (Article 4 - 2)	YES
EN 45545-2 Results	R22 HL2, R23 HL3
Flammability	UL 94 V0
Hazardous good	No
Material	Polyamide 6.6 + Polyamide 6 V0 (PA666V0), Stainless Steel (SS304)
Operating Temperature - °C	-40 °C to +85 °C
Specifications	RoHS EN 45545-2
Specifications	EN 45545, EN 45545-2:2013, NFPA130: 2017
UL Listed (US and Canada)	No
UL Recognized (US and Canada)	No

UV-Resistant (Yes/No)	Yes
-----------------------	-----

Logistics and Packaging

▼

More Information

▲

ETIM 6.0	EC000127
ETIM 7.0 Key	EC000127
UNSPSC Key	39121702

Accessories

▲

RCTT
151-01529
Ratchet P-Clamp



RCINSERTB
151-01531
Ratchet P-Clamp



Similar products

▲

RCB180SM10
151-01390
Ratchet P-Clamp, B-Series



RCB180SM6
151-01645
Ratchet P-Clamp, B-Series



RCBHANGER
151-02875
Ratchet P-Clamp, B-Series



151-01440

Ratchet P-Clamp, B-Series



151-01441

Ratchet P-Clamp, B-Series



151-01443

Ratchet P-Clamp, B-Series



Show all 

© HellermannTyton 2019

HellermannTyton

Server error

Contact 