



stewart

CONNECTOR

a bel group


USB Type-C Jacks

USB Type-C Jacks

- Available in right angle mount with two PCB thickness options
- Has both SMT and Through hole signal pins
- Operating temperature: -40°C to 105°C.
- Operating voltage: 20V
- Current Rating: 5A MAX
- Data Rates: 10Gbps
- Packaged in Tape and Reel



Part Number	Orientation	PCB Thickness
SS-52400-002	Horizontal	0.039" [1.00mm]
SS-52400-003	Horizontal	0.063" [1.60mm]

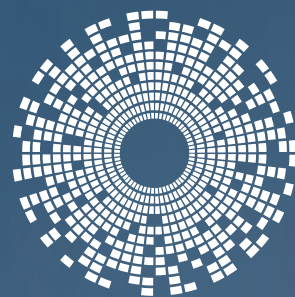

stewart

CONNECTOR

a bel group

belfuse.com/stewart-connector