

Construction Glass cartridge, silvered caps.
Specification DIN 41571, Sheet 2.
Marking Manufacturers Mark, Rated voltage, Rated current, Characteristic symbol category C.
Range 800 mA to 1.25 A
Voltage Rating 250 V ac 250 V dc.
Breaking Capacity 20 A dc at 250 V, DIN CATEGORY C.
 80A ac at 250 V.
Endurance 1 h at 1.5 I_n
Service Temperature 0°C to + 35°C.

Performance Data

Current	Total operating time	
	min	max
1.5 I _n	60 mins	—
2.1 I _n	—	2 mins
4 I _n	60 ms	2 s
10 I _n	20 ms	70 ms


Approximate Weight 0.8 kg per 1000 fuselinks.

Preferred Ratings

I_n
 800 mA
 1 A
 1.25 A

Other ratings may be available.

Performance Envelope — Combined Ratings

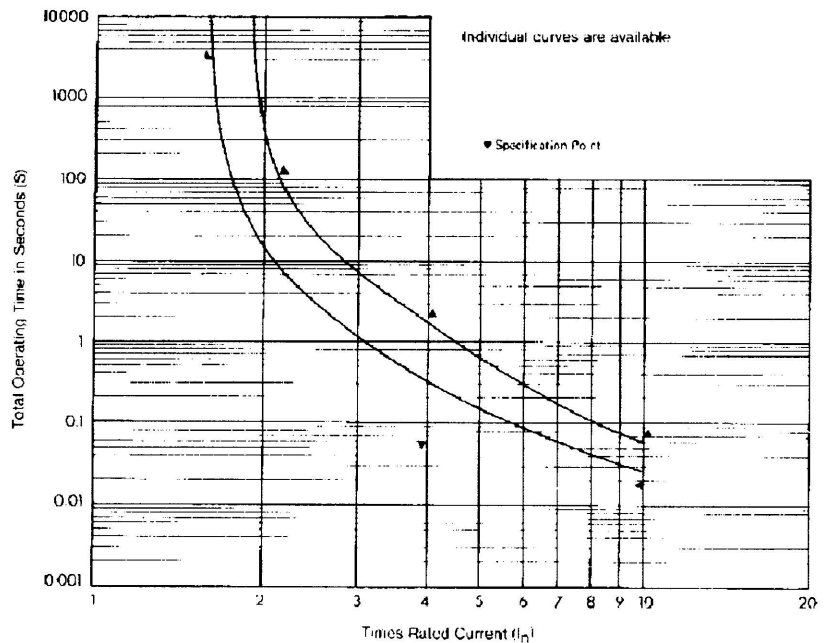

All rights reserved and any use and advice rendered in connection therewith, subject only to the Company's Standard Conditions of Sale.