


**KEMET Part Number: SBC7-472-281**  
(UPIN7472281000)

KEMET, SBC7, Power, 4700 uH, 10%, 10mm

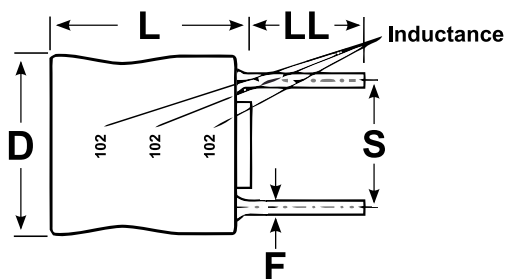

#### General Information

<b>Series:</b>	SBC7
<b>Style:</b>	Through-Hole
<b>Description:</b>	Radial Leaded, Ferrite Power Inductors
<b>Features:</b>	DC-DC Converters, Nickel-Zinc (NiZn) Ferrite Core
<b>RoHS:</b>	Yes
<b>Lead:</b>	Wire Leads
<b>Core:</b>	Ferrite
<b>Miscellaneous:</b>	Pin Lead Terminal

#### Dimensions

<b>D</b>	15mm MAX
<b>L</b>	17.5mm MAX
<b>S</b>	10mm +/-0.5mm
<b>LL</b>	8.5mm +/-1mm
<b>F</b>	1mm NOM

#### Specifications

<b>Inductance:</b>	4700 uH (0.01 MHz)
<b>Inductance Tolerance:</b>	10%
<b>Temperature Range:</b>	-20/+105°C
<b>Shielded:</b>	No
<b>Current:</b>	0.28 Amps
<b>DC Resistance:</b>	4.83 Ohms

#### Packaging Specifications

<b>Weight:</b>	10 g
<b>Packaging:</b>	Bulk
<b>Packaging Quantity:</b>	1000