

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2065232243](#)
Status: **Active**
Overview: [Mini50 Connection Systems](#)
Description: Mini50 Unsealed Receptacle, Dual Row, UL94-HB, with CPA, 24 Circuits, Polarization Option C, Dark Gray

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-31301-538-001 \(PDF\)](#)
[Product Specification 2065230000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification 2065230000-AS-000 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	206523
Application	Automotive, Power, Wire-to-Board
Overview	Mini50 Connection Systems
Polarization	C
Product Name	Mini50
UPC	191128857161


Physical

Circuits (maximum)	24
Color - Resin	Gray (Dark)
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +100°C

Material Info

Reference - Drawing Numbers

Application Specification	2065230000-AS-000
Packaging Specification	PK-31301-538-001
Product Specification	2065230000-PS-000
Sales Drawing	2065230000-000

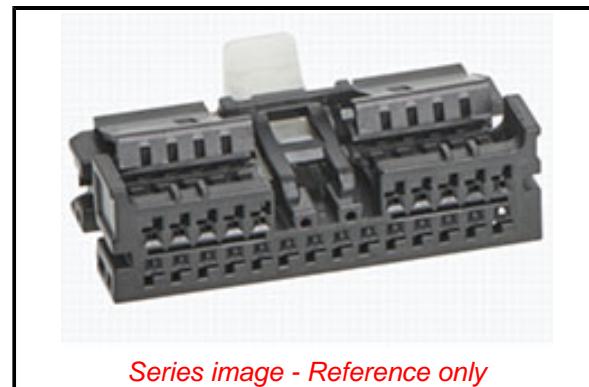

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[206523](#) Series

Mates With

Mini50 Surface Mount Header [348978242](#)
, [348979242](#)
 Mini50 Vertical Through-Hole Header [348250242](#) , [348259242](#)
 Mini50 Right-Angle Through-Hole Header [348260242](#) , [348269242](#)

Use With

CTX50 Unsealed Terminals [560023](#)