

# Panduit® Type C Wiring Duct Covers in 2 Meter Length for Taller Enclosures

## Applications:

Control Panel building with taller enclosures typically exceeding 72" in height.

## Problem Description:

In taller industrial and electrical enclosures the standard 6ft. long wiring duct and cover is not long enough to span the entire distance from top to bottom. Panel builders are forced to use two pieces of duct and cover to span the entire distance. This creates a visible seam in a single run of wiring duct. This doesn't provide the aesthetics that most panel builders are looking for.


## Panduit Solution:

Provide a longer wiring duct cover that can span the distance from top to bottom in the taller enclosures. This enables the Panel Builder to cover up the two wiring duct base pieces with one piece of duct cover. It provides a more aesthetically pleasing installation with no visible seams or gaps in a single run. It enables the Panel Builder to be more efficient by using multiple pieces of wiring duct bases and reducing scrap.

## Typical Applications:

There are many manufacturers that produce enclosures in excess of 72" in height that can take advantage of the longer 2m covers. Here are some specific examples:

- Hoffman Mild Steel and Stainless Steel, Free-Stand Enclosures that are 86" and 90" in Height.
- Hoffman ProLine series Enclosures that are 2000mm and 2200mm in Height.
- Rittal TS 8 Enclosure Systems that 2000mm and 2200 mm in Height.
- Rittal SE 8 Enclosure Systems that are 2000mm in Height.

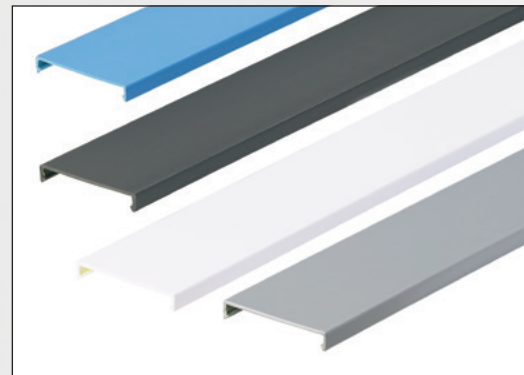

Part Number	Width (In.)	Length (m)
C1LG2	1"	2m
C1.5LG2	1.5"	2m
C2LG2	2"	2m
C3LG2	3"	2m
C4LG2	4"	2m

Compatible with Wiring Duct Types:  
Type F Narrow Finger, Type G Wide Finger, Type D Round Hole, Type FS Solid Wall.

Part numbers shown for Light Gray (LG). Also available in White (WH), Black (BL), and Intrinsic Blue (IB).

Material: Lead-free PVC

UL recognize continuous use temperature: 122°F (50°C)

UL 94 flammability rating of V-0

# Panduct® Type C Wiring Duct Covers in 2 Meter Length for Taller Enclosures

## Example:




Hoffman Free Stand, Multi-Door, Type 12, 3 doors

### External Dimensions:

86"H x 112"W x 20"D

### Mounting Plate(s) Dimensions:

78"H x 70"W and 78"H x 34"W

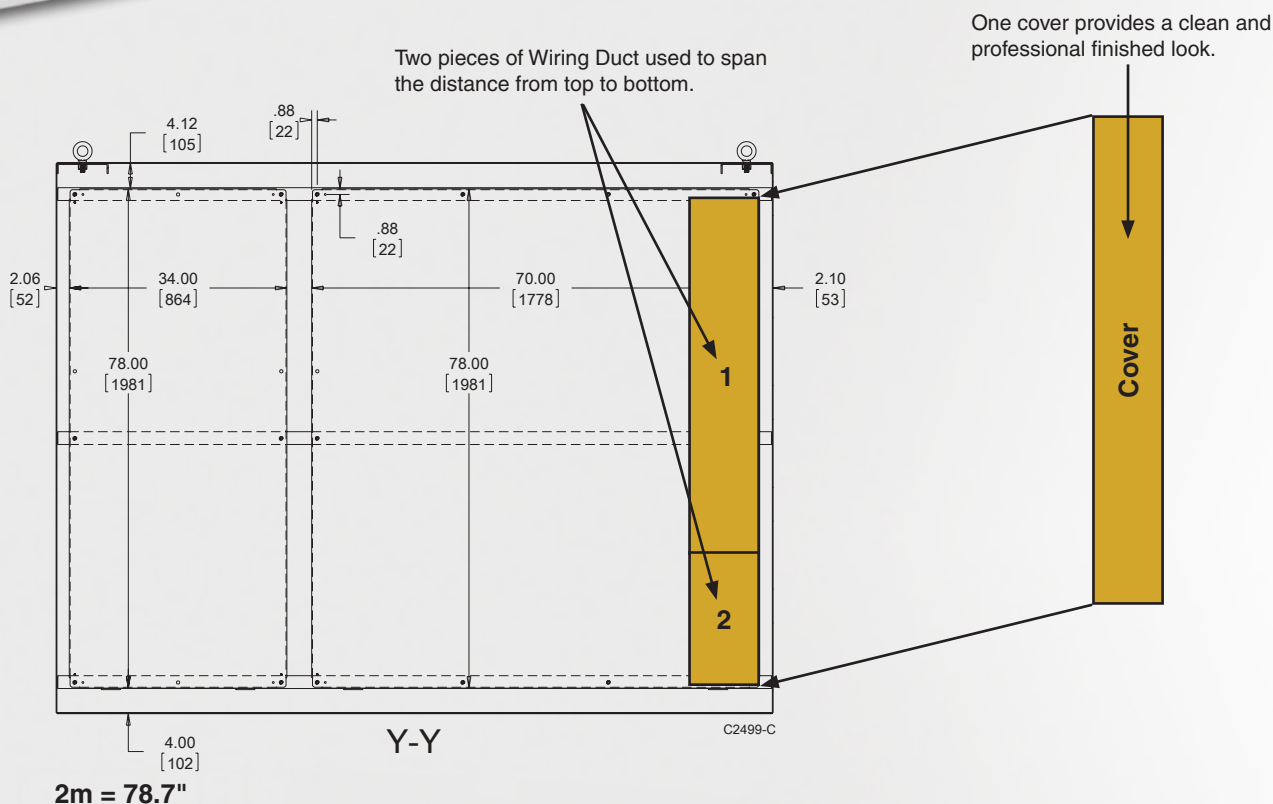

## WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT CANADA  
Markham, Ontario  
cs-cdn@panduit.com  
Phone: 800.777.3300

PANDUIT EUROPE LTD.  
London, UK  
cs-emea@panduit.com  
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.  
Republic of Singapore  
cs-ap@panduit.com  
Phone: 65.6305.7575

PANDUIT JAPAN  
Tokyo, Japan  
cs-japan@panduit.com  
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA  
Guadalajara, Mexico  
cs-la@panduit.com  
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.  
Victoria, Australia  
cs-aus@panduit.com  
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

For more information

Visit us at [www.panduit.com](http://www.panduit.com)

Contact Customer Service by email: [cs@panduit.com](mailto:cs@panduit.com)  
or by phone: 800.777.3300

**PANDUIT®**

©2016 Panduit Corp.  
ALL RIGHTS RESERVED.  
WDAN01--SA-ENG  
10/2016