

Interface module - DFLK-D62 SUBH/S - 2300863

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




VARIOFACE panel feed-through module, for direct coupling of single signal lines of up to 2.5 mm², with D-Subminiature pin strip and screw connection, number of positions 62

Your advantages

- ✓ 62-pos. pin strip
- ✓ According to IEC 60807-2
- ✓ Screw connection
- ✓ 1:1 connection
- ✓ D-SUB 4-40 UNC thread

RoHS

Key Commercial Data

| | |
|--------------------------------------|---|
| Packing unit | 10 pc |
| GTIN |  4 017918 903213 |
| GTIN | 4017918903213 |
| Weight per Piece (excluding packing) | 189.230 g |
| Custom tariff number | 85369010 |
| Country of origin | Germany |
| Note | Made to Order (non-returnable) |

Technical data

Dimensions

| | |
|--------|---------|
| Width | 40.4 mm |
| Height | 180 mm |

Ambient conditions

| | |
|---|------------------|
| Ambient temperature (operation) | -20 °C ... 50 °C |
| Ambient temperature (storage/transport) | -20 °C ... 70 °C |

General

Interface module - DFLK-D62 SUBH/S - 2300863

Technical data

General

| | |
|---------------------------------|---------------------------|
| Nominal voltage U_N | 25 V AC |
| | 50 V DC |
| Max. perm. current (per branch) | 0.5 A |
| Number of positions | 62 |
| Status display | No |
| Mounting position | any |
| Assembly instructions | In rows with zero spacing |

Connection data

| | |
|----------------------------------|---|
| Connection name | Field level |
| Connection in acc. with standard | IEC / EN |
| Connection method | Screw connection |
| Stripping length | 8 mm |
| Screw thread | M3 |
| Conductor cross section solid | 0.2 mm ² ... 4 mm ² |
| Conductor cross section flexible | 0.2 mm ² ... 2.5 mm ² |
| Conductor cross section AWG | 24 ... 12 |

Connection data 2

| | |
|-----------------------|------------------|
| Connection name | Controller level |
| Connection method | D-SUB pin strip |
| Number of connections | 1 |
| Number of positions | 62 |

Supported controller

| | |
|------------|-------------|
| Controller | Teleperm XP |
|------------|-------------|

Standards and Regulations

| | |
|-----------------------|---------------------------------------|
| Designation | Air clearances and creepage distances |
| Standards/regulations | DIN EN 50178 |
| Rated surge voltage | basic insulation |
| Pollution degree | 2 |
| Overvoltage category | II |


Environmental Product Compliance

| | |
|------------|---|
| REACH SVHC | Lead 7439-92-1 |
| China RoHS | Environmentally Friendly Use Period = 50 |
| | For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration" |

Drawings


Interface module - DFLK-D62 SUBH/S - 2300863

Dimensional drawing

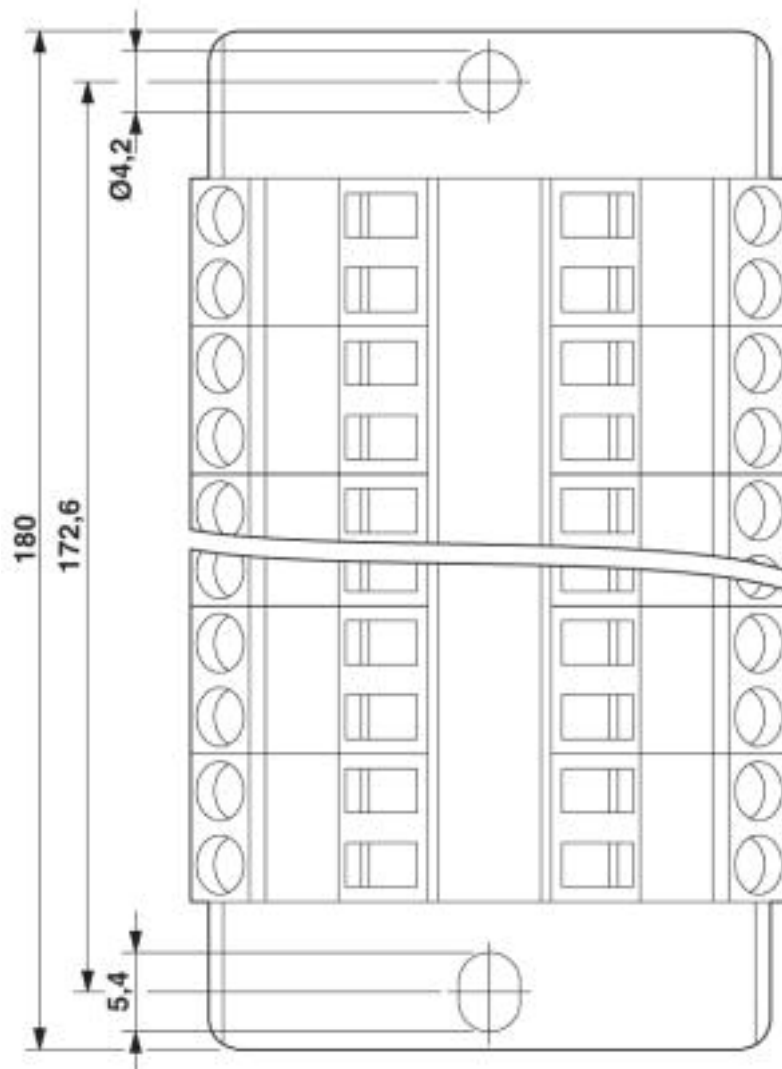


Interface module - DFLK-D62 SUBH/S - 2300863

Dimensional drawing

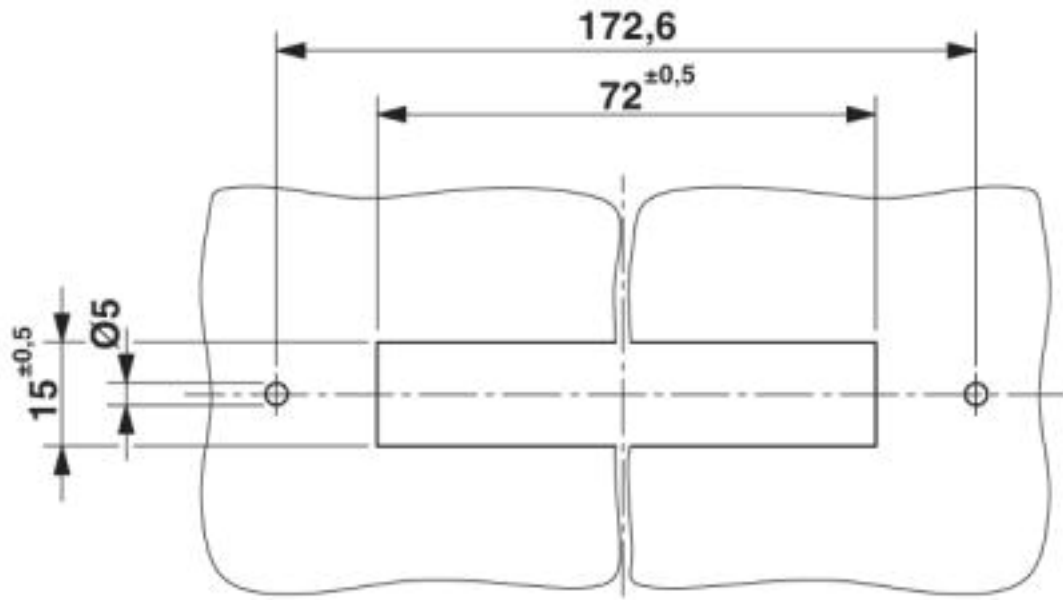

Interface module - DFLK-D62 SUBH/S - 2300863

Dimensional drawing

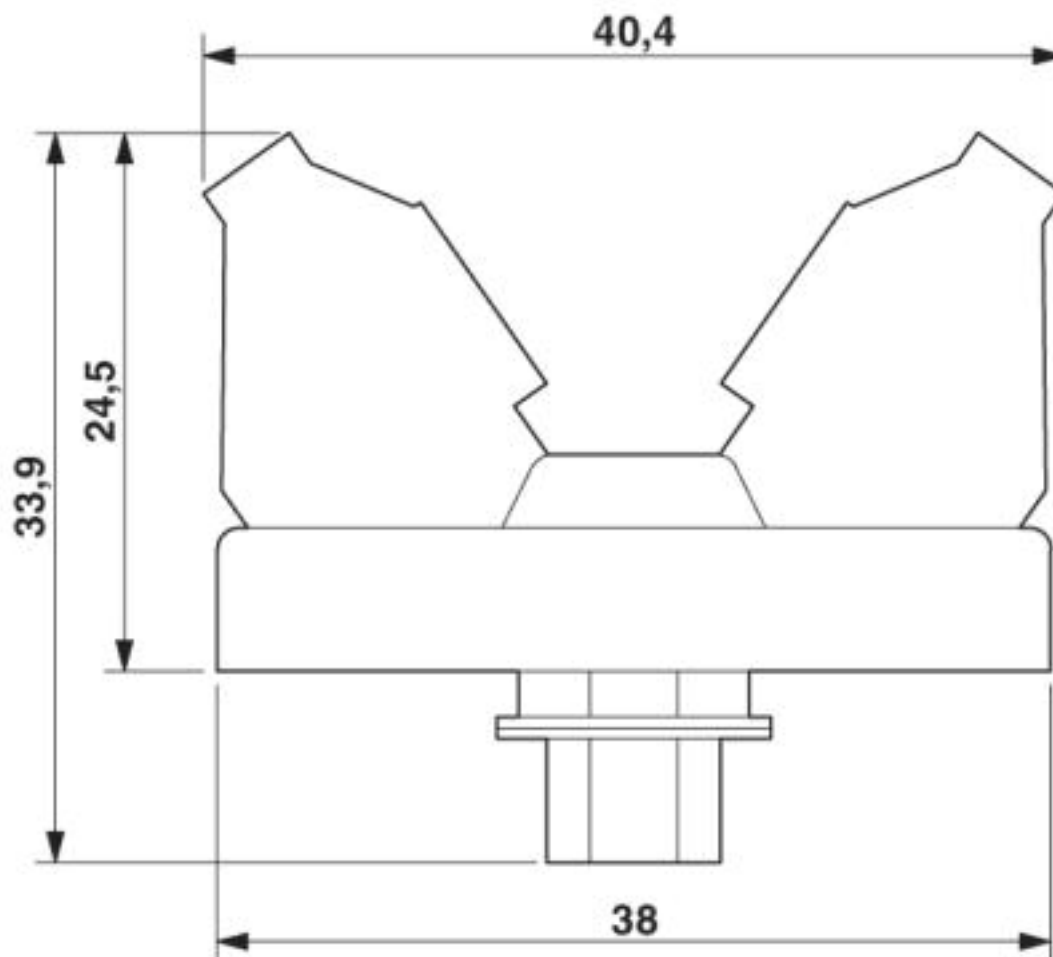

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 27250300 |
| eCl@ss 4.1 | 27250300 |
| eCl@ss 5.0 | 27250300 |
| eCl@ss 5.1 | 27250300 |
| eCl@ss 6.0 | 27242600 |
| eCl@ss 7.0 | 27141152 |
| eCl@ss 8.0 | 27141152 |
| eCl@ss 9.0 | 27141152 |

ETIM

| | |
|----------|----------|
| ETIM 4.0 | EC002780 |
| ETIM 5.0 | EC002780 |
| ETIM 6.0 | EC002780 |

Interface module - DFLK-D62 SUBH/S - 2300863

Classifications

ETIM

| | |
|----------|----------|
| ETIM 7.0 | EC002780 |
|----------|----------|

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 30211824 |
| UNSPSC 7.0901 | 39121421 |
| UNSPSC 11 | 39121421 |
| UNSPSC 12.01 | 39121421 |
| UNSPSC 13.2 | 39121432 |
| UNSPSC 18.0 | 39121432 |
| UNSPSC 19.0 | 39121432 |
| UNSPSC 20.0 | 39121432 |
| UNSPSC 21.0 | 39121432 |

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

| | | |
|-----|---|--------------------------|
| EAC |  | RU C- DE.A*30.B.01742 |
|-----|---|--------------------------|

Accessories

Accessories

System cable

Cable - CABLE-D62SUBH/B/B/ 40/K4G/GK2 - 2319090



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 0.4 m

Interface module - DFLK-D62 SUBH/S - 2300863

Accessories

Cable - CABLE-D62SUBH/B/B/ 60/K4G/GK2 - 2319087



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 0.6 m

Cable - CABLE-D62SUBH/B/B/ 200/K4G/GK2 - 2312000



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 2 m

Cable - CABLE-D62SUBH/B/B/ 300/K4G/GK2 - 2311991



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 3 m

Cable - CABLE-D62SUBH/B/B/ 400/K4G/GK2 - 2311988



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 4 m

Cable - CABLE-D62SUBH/B/B/ 500/K4G/GK2 - 2311975



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 5 m

Interface module - DFLK-D62 SUBH/S - 2300863

Accessories

Cable - CABLE-D62SUBH/B/B/ 750/K4G/GK2 - 2311962



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 7.5 m

Cable - CABLE-D62SUBH/B/B/1000/K4G/GK2 - 2311959



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 10 m

Cable - CABLE-D62SUBH/B/B/1250/K4G/GK2 - 2311946



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 12.5 m

Cable - CABLE-D62SUBH/B/B/1500/K4G/GK2 - 2311933



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 15 m

Cable - CABLE-D62SUBH/B/B/1750/K4G/GK2 - 2311920



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 17.5 m

Interface module - DFLK-D62 SUBH/S - 2300863

Accessories

Cable - CABLE-D62SUBH/B/B/2000/K4G/GK2 - 2311917



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 20 m

Cable - CABLE-D62SUBH/B/B/3000/K4G/GK2 - 2901375



Assembled, shielded round cable, with 62-pos. HD D-SUB female connector at both ends; cable length: 30 m
