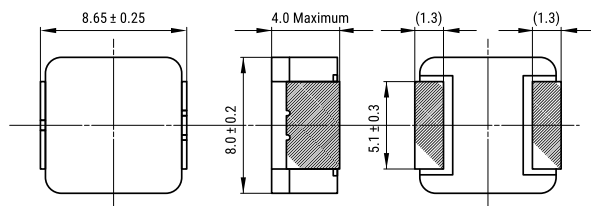


KEMET, MPXV, Power, 1000 nH, 20%

**Dimensions**

<b>L</b>	8.65mm +/-0.25mm
<b>W</b>	8mm +/-0.2mm
<b>T</b>	4mm MAX
<b>LL</b>	1.3mm NOM
<b>G</b>	5.1mm +/-0.3mm

**Packaging Specifications**

<b>Packaging:</b>	T&R, 330mm
<b>Packaging Quantity:</b>	1000

**General Information**

<b>Series:</b>	MPXV
<b>Style:</b>	SMD
<b>Description:</b>	Surface Mount Inductor
<b>Features:</b>	Power Inductors
<b>Qualifications:</b>	AEC-Q200
<b>AEC-Q200:</b>	Yes
<b>Core:</b>	Composite
<b>Miscellaneous:</b>	40 (K) Temperature Rise Max.

**Specifications**

<b>Inductance:</b>	1 uH (100 KHz)
<b>Inductance Tolerance:</b>	20%
<b>Temperature Range:</b>	-55/+155°C
<b>Shielded:</b>	Yes
<b>Current:</b>	20.8 A (Irms, 40C Rise By Self Heating), 19.5 A (Isat, 20% Drop In Inductance), 28 A (Isat, 30% Drop In Inductance)
<b>DC Resistance:</b>	4.2 mOhms
<b>Self-Resonant Frequency:</b>	40 MHz