

SYLVANIA Luminaires

10" Canopy



Product Features


- Slim, lightweight design
- Easy to install with hinged mounting plate
- Durable housing
- Energy savings of up to 79% compared to traditional sources
- High efficacy meets DLC Premium requirements

Wattage Comparison Chart

Traditional Source	Traditional System Wattage	LED System Wattage	Energy Savings
35 W HPS	42	20	52%
50 W HPS	62	20	68%
70 W HPS	91	20	67%
70 W HPS	91	40	56%
100 W HPS	120	40	67%
100 W MH	130	40	69%
150 W HPS	170	40	76%
150 W MH	188	40	79%
150 W HPS	170	55	68%
150 W MH	188	55	71%
175 W MH	210	55	74%

Catalog #	Type
Project	
Notes	
Date	
Prepared by	

Dimensions

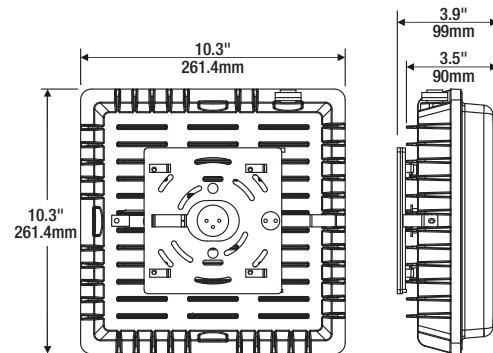

Specifications

Weight: 5.7 lbs (2.3kg)

Construction: Die Cast aluminum housing with powder coat paint. The standard colors are bronze or white.

LED System: LED system with a life rating of >50,000 hours at L₇₀ @ 25°C. Luminaire efficacy up to 120 LPW.

Electrical: Offered in 20, 40, and 55 watts, the luminaire is designed to operate through the 120-277 Vac universal voltage range. The LED driver is a constant current device. The power factor is ≥90% and THD is ≤20%.

Color Characteristics: CRI >70; CCT of 4000K or 5000K.

Optics: Type V distribution with UV resistant polycarbonate lens.

Installation: Luminaire mounts to recessed outlet box or can be pendant mounted (accessories not included).

Operating Temperature: -40°F to +104°F (-40°C to +40°C).

Listings: cULus classified to UL1598 rated for wet locations.

Warranty: Standard 5-year luminaire warranty (LEDLUM002).

Note: Specifications subject to change without notice. IES files available online.



Ordering Guide

Item Number:

CANOPY	3A	/	XXX	XXX	7	XX	/	10S	5	/	XX
Product Name	Generation		Wattage (UNV)	Voltage	CRI	Color Temp (CCT)		Shape	Distribution		Color Finish
CANOPY	3A		020 = 20 Watts 040 = 40 Watts 055 = 55 Watts	UNV = 120-277V	7 = >80	40 = 4000K 50 = 5000K		10S = 10" Square	5 = Type V		BZ = Bronze WH = White



Ordering Information

Item Number	Ordering Abbreviation	Finish	Power (W)	Input Voltage	CRI	Color Temp (CCT)	Lumens	LPW	DLC
60151	CANOPY3A/020UNV740/10S5/WH	White	20	120-277	>70	4000K	2300	115	Pm
60152	CANOPY3A/020UNV750/10S5/WH	White	20	120-277	>70	5000K	2300	115	Pm
60153	CANOPY3A/040UNV740/10S5/WH	White	40	120-277	>70	4000K	4800	120	Pm
60154	CANOPY3A/040UNV750/10S5/WH	White	40	120-277	>70	5000K	4800	120	Pm
60155	CANOPY3A/055UNV740/10S5/WH	White	55	120-277	>70	4000K	6300	114	Pm
60156	CANOPY3A/055UNV750/10S5/WH	White	55	120-277	>70	5000K	6300	114	Pm
60157	CANOPY3A/020UNV740/10S5/BZ	Bronze	20	120-277	>70	4000K	2300	115	Pm
60158	CANOPY3A/020UNV750/10S5/BZ	Bronze	20	120-277	>70	5000K	2300	115	Pm
60159	CANOPY3A/040UNV740/10S5/BZ	Bronze	40	120-277	>70	4000K	4800	120	Pm
60160	CANOPY3A/040UNV750/10S5/BZ	Bronze	40	120-277	>70	5000K	4800	120	Pm
60161	CANOPY3A/055UNV740/10S5/BZ	Bronze	55	120-277	>70	4000K	6300	114	Pm
60162	CANOPY3A/055UNV750/10S5/BZ	Bronze	55	120-277	>70	5000K	6300	114	Pm

LEDVANCE LLC
 200 Ballardvale Street
 Wilmington, MA 01887 USA
 Phone 1-800-LIGHTBULB (1-800-544-4828)
www.sylvania.com

SYLVANIA and LEDVANCE are registered trademarks.
 All other trademarks are those of their respective owners.
 Licensee of product trademark SYLVANIA in general lighting.
 Specifications subject to change without notice.

 /sylvania  /sylvania

© 2018 LEDVANCE LLC

