



9W

VT-8056 9W LED UP/DOWN OUTDOOR SOFT LIGHT-MEDIUM
COLORCODE:4000K GREY BODY

Lumens
400

Beam Angle
90

Dimensions
173x81x46mm

Day White
SKU:8240

2 YEARS
WARRANTY


SENSOR
COMPATIBLE



Technical Information

| | |
|----------------|----------------|
| Instant Start: | 0-100% in lt1s |
| Watts: | 9 |
| Lumens: | 400 |
| Beam Angle: | 90 |
| Unit Color: | Grey |
| Body Type: | PC |
| Long life: | 30,000 Hours |
| LED Chip Type: | SMD2835 |

| | |
|------------------------|---------------------|
| IP Rating: | IP65 |
| Dimmable: | No |
| Warranty (Years): | 2 |
| PF: | >0.9 |
| CRI: | >80 |
| Operation Temperature: | -20 to +45°C |
| Input Power: | AC:100-240V,50/60Hz |
| Sensor Compatibility: | Yes |

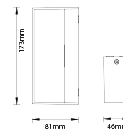

Features

- ✓ Perfect Soft lighting option for your Landscape,Garden & Patios
- ✓ Splendid designs made of high endurance PC material
- ✓ High quality PC material for Diffused and Controlled light output
- ✓ IP65 rated solid ingress protection
- ✓ Applications - Outdoor, Façade, Residential, Restaurants, Building and many more



Note:

Suitable & Recommended for maximum daily use of 10-12 hours, usage beyond this would void the warranty

Packaging

Unit Details

| | |
|----------------------|----------|
| Gross Weight(GW) Kgs | 0.358 |
| Length(Box)mm | 180 |
| Width(Box)mm | 90 |
| Height(Box)mm | 55 |
| Unit CBM | 0.000891 |

Listing Details

| | |
|----------------|---------------|
| EAN Code | 3800157625807 |
| Commodity Code | 9405403990 |



Master Box Packaging

| | |
|---------------------------------|------|
| Master Box Qty (Pcs Per Carton) | 20 |
| Qty Per Pallet | 1440 |

READY STOCKS IN
UK & EU



Dispatch within
24 Hours

www.vtacexports.com

OUR PRODUCTS ARE
CURRENTLY SOLD IN OVER
70
COUNTRIES