

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200900032

Status:


Active

Overview:

Brad Nano-Change (M8) Products

Description:

Nano-Change (M8) Receptacle, 4 Poles, M8 x 0.5 Mounting Threads, Male (Straight) to 22 AWG Leads, 0.30m (11.81") Length

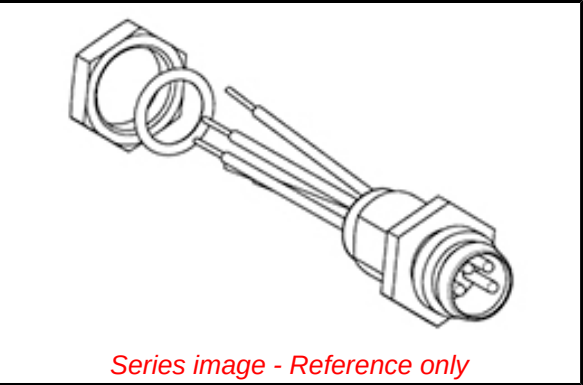

Series image - Reference only

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	120090
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Nano-Change (M8) Products
Product Name	Nano-Change (M8)
Type	Single Ended (pigtail)
UPC	78678833057
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	None
Length	0.30m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M8 x 0.5
Net Weight	9.071/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	24
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	60V AC / 75V DC
Material Info	
Engineering Number	4R4P06A27C300
Reference - Drawing Numbers	
Sales Drawing	SD-120090-040

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with

Exemption 6(c),7(c)-I

REACH SVHC

Contained Per -

ED/01/2018 (15

January 2018)

2,4-Di-tert-butyl-6-(5-

chlorobenzotriazol-2-

yl)p

Bisphenol-A

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120090 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION