



H K Wentworth Group
Distributed and Supported in
the UK



hakko.com - hakko.co.uk

Packing List



FM2024 Desoldering Tool (FM2024-02)
Nozzle **NOT** included

Handle (B2872)



Ceramic paper filter (10 pcs.) (A1613)



Filter pipe assembly (A1511)



Nozzle remover (B2876)



FH200-05 Iron Stand with 599B Cleaning
Wire + Pot



Connecting cable (B3253)



Cleaning Drill (B2873)



Desolder Control Box (C1529)



FM2024-35

Specifications:

FM2024 Desoldering Tool

Power consumption	70W (24V)
Temperature range	350 to 450°C
Nozzle to ground resistance	<2Ω
Nozzle to ground potential	<2mV
Heating element	Composite heater
Cord length	1.2m
Total length	180mm (with Φ1.0mm nozzle)
Total length	180mm (with Φ1.0mm nozzle)

* Total length and weight (w/o cord)


Desoldering Control Box (DCB C1529)

Power consumption	12W
Output	24V
Vacuum Generator Vacuum Pressure	Ejector type Max. 93kPa (700mmHg)
Suction Flow	20L/min
Tip to Ground Potential	< 2mV
Applied Air Pressure	490kPa (5.0kgf/cm ²) When in use (trigger or button is pressed)
Compressed Air Consumption	46L/min
Outer Dimensions	119(W) x 45(H) x 172(D)mm
Weight	1.2kg


Nozzles:

The FM2024 is NOT supplied with desoldering nozzles. These are available to purchase separately:


N3 Series

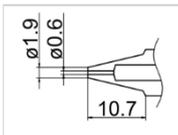


N3-06 Nozzle
Size Φ0.6

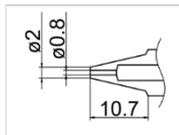


N3-08 Nozzle
Size Φ0.8

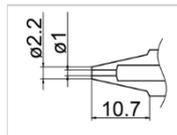


N3-10 Nozzle
Size Φ1.0

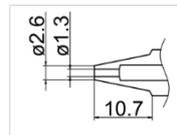


N3-13 Nozzle
Size Φ1.3

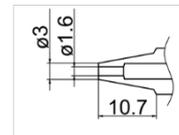


N3-16 Nozzle
Size Φ1.6

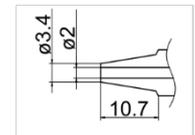

N3-20 Nozzle
Size Φ2.0

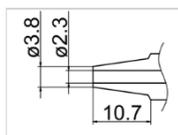

N3-23 Nozzle
Size Φ2.3

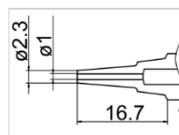

N3-L10 Nozzle
Size Φ1.0(Long)



H K Wentworth Group
Distributed and Supported in
the UK