


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0152670249](#)
Status: **Active**
Overview: Premo-Flex Cable Jumpers
Description: 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 10 Circuits, 0.076m Cable Length, Tin (Sn) Plating

Documents:

Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-15267-001-001 (PDF)	Product Literature (PDF)
Packaging Specification PK-15267-001-001 (PDF)	

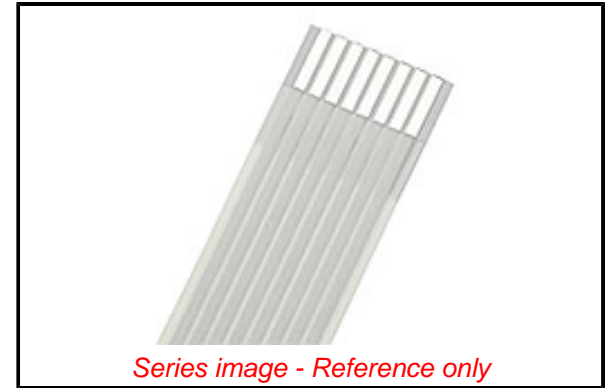

General

Product Family	Cable
Series	15267
Comments	Contacts on the same side, Type A, Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	Premo-Flex Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	884982441118

Physical

Cable Length	0.076m
Circuits (Loaded)	10
Circuits (maximum)	10
Material - Plating Mating	Tin
Net Weight	0.584/g
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

Electrical

Current - Maximum per Contact	1.2A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-15267-001-001
Product Specification	PS-15267-001-001
Sales Drawing	SD-15267-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15267 Series](#)

Mates With

Easy-On FFC/FPC Connector:
[522071033](#) , [522711079](#) , [526101033](#) , [526101034](#)