


## Insert label - PABA WH/23 - 1013779

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Insert label, Strip, white, unlabeled, can be labeled with: CMS-P1-PLOTTER, mounting type: thread on, cable diameter range: 1.5 ... 35 mm, lettering field size: 23 x 4 mm, Number of individual labels: 20

### Key Commercial Data

|                                      |   |
|--------------------------------------|---|
| Packing unit                         | 10 pc   |
| Minimum order quantity               | 10 pc   |
| GTIN                                 | <br>4 017918 013967 |
| GTIN                                 | 4017918013967   |
| Weight per Piece (excluding packing) | 5.690 g   |
| Custom tariff number                 | 39269097  |
| Country of origin                    | China   |

### Technical data

#### Dimensions

|                |                  |
|----------------|------------------|
| Length (b)     | 4 mm             |
| Width (a)      | 23 mm            |
| Cable diameter | 1.5 mm ... 35 mm |

#### Ambient conditions

|                                 |                  |
|---------------------------------|------------------|
| Ambient temperature (operation) | -15 °C ... 65 °C |
|---------------------------------|------------------|

#### General

|  |                             |
|--|-----------------------------|
| Note                                   | Can be labeled with CMS     |
| Color                                  | white                       |
| Flammability rating according to UL 94 | V0                          |
| Material                               | ABS                         |
| Wipe resistance                        | DIN EN 61010-1 (VDE 0411-1) |
| Number of individual labels            | 20                          |
| Number of individual labels per row    | 1                           |

# Insert label - PABA WH/23 - 1013779

## Technical data

### General


|                       |           |
|-----------------------|-----------|
| Marking mounting type | thread on |
|-----------------------|-----------|

### Standards and Regulations

|  |                             |
|--|-----------------------------|
| Wipe resistance                        | DIN EN 61010-1 (VDE 0411-1) |
| Flammability rating according to UL 94 | V0                          |

## Drawings

Dimensional drawing

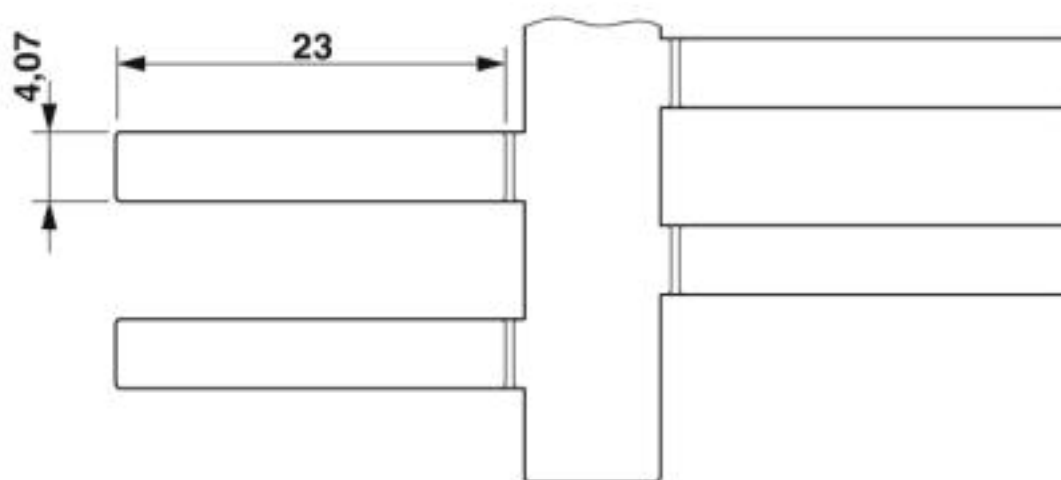

## Classifications

### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27400629 |
| eCl@ss 4.0    | 24190200 |
| eCl@ss 4.1    | 24190200 |
| eCl@ss 5.0    | 27149100 |
| eCl@ss 5.1    | 27141100 |
| eCl@ss 6.0    | 27149100 |
| eCl@ss 7.0    | 27149129 |
| eCl@ss 8.0    | 27400401 |
| eCl@ss 9.0    | 27400629 |

### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC000761 |
| ETIM 3.0 | EC000761 |
| ETIM 4.0 | EC001530 |
| ETIM 5.0 | EC001288 |
| ETIM 6.0 | EC001288 |

## Insert label - PABA WH/23 - 1013779

### Classifications

#### ETIM

|          |          |
|----------|----------|
| ETIM 7.0 | EC001288 |
|----------|----------|

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211811 |
| UNSPSC 7.0901 | 39121410 |
| UNSPSC 11     | 39121410 |
| UNSPSC 12.01  | 39121410 |
| UNSPSC 13.2   | 39131504 |
| UNSPSC 18.0   | 39131504 |
| UNSPSC 19.0   | 39131504 |
| UNSPSC 20.0   | 39131504 |
| UNSPSC 21.0   | 39131504 |