

## Mounting frame - VS-SI-EB-EMV-2 - 1656495

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Mounting frame, for two front plates or sockets, metal frame, matt nickel-plated, electrically conductive, transparent cover



RoHS

### Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356029865
Weight per Piece (excluding packing)	402.400 g
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### Dimensions

Height	35 mm
Width	130 mm
Length	120 mm
Length of the assembly cutout	91 mm
Width of the assembly cutout	117 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP65
Ambient temperature (operation)	-10 °C ... 60 °C

#### General

Note	With lockable pressure lock
Type	For 2 front plates
Color	transparent
Housing material	Zinc alloy
Housing surface material	Nickel-plated

# Mounting frame - VS-SI-EB-EMV-2 - 1656495

## Technical data

### General

Flammability rating according to UL 94	V0
Assembly instructions	Suitable for panel thicknesses 1 mm ... 5 mm

### Standards and Regulations


Flammability rating according to UL 94	V0
--	----

### Environmental Product Compliance

	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings


Dimensional drawing

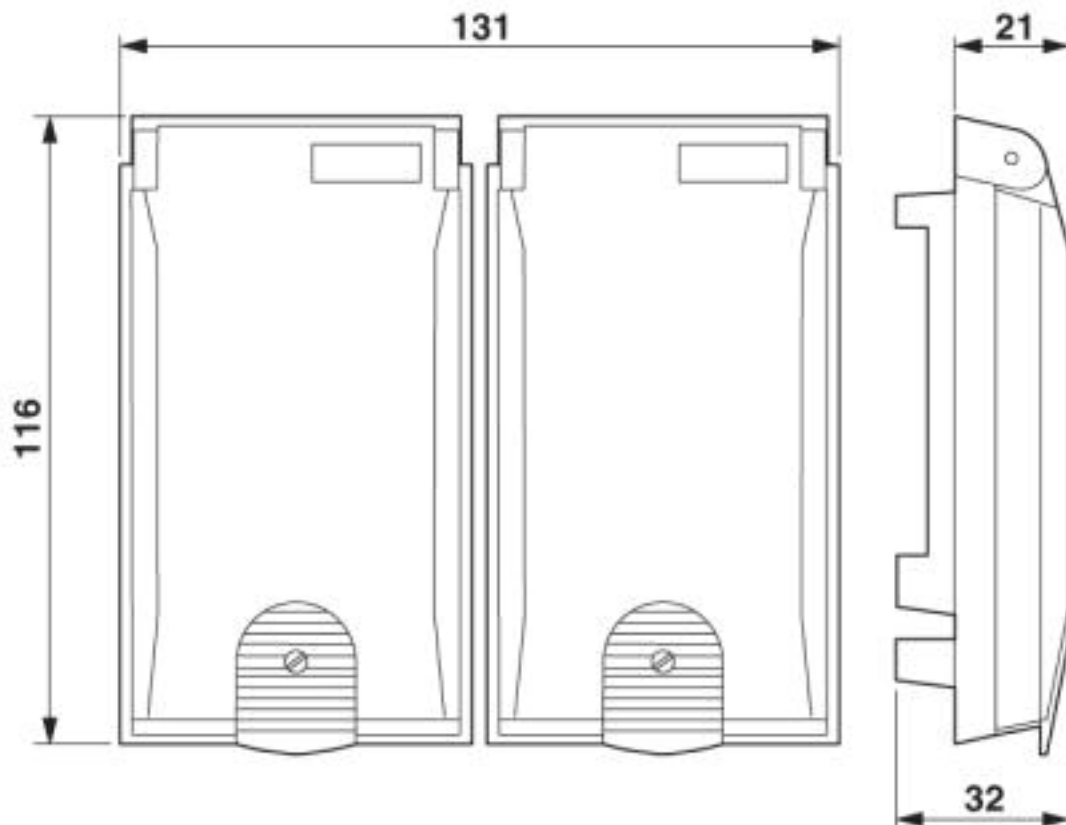

Dimensional drawing

# Mounting frame - VS-SI-EB-EMV-2 - 1656495

Dimensional drawing

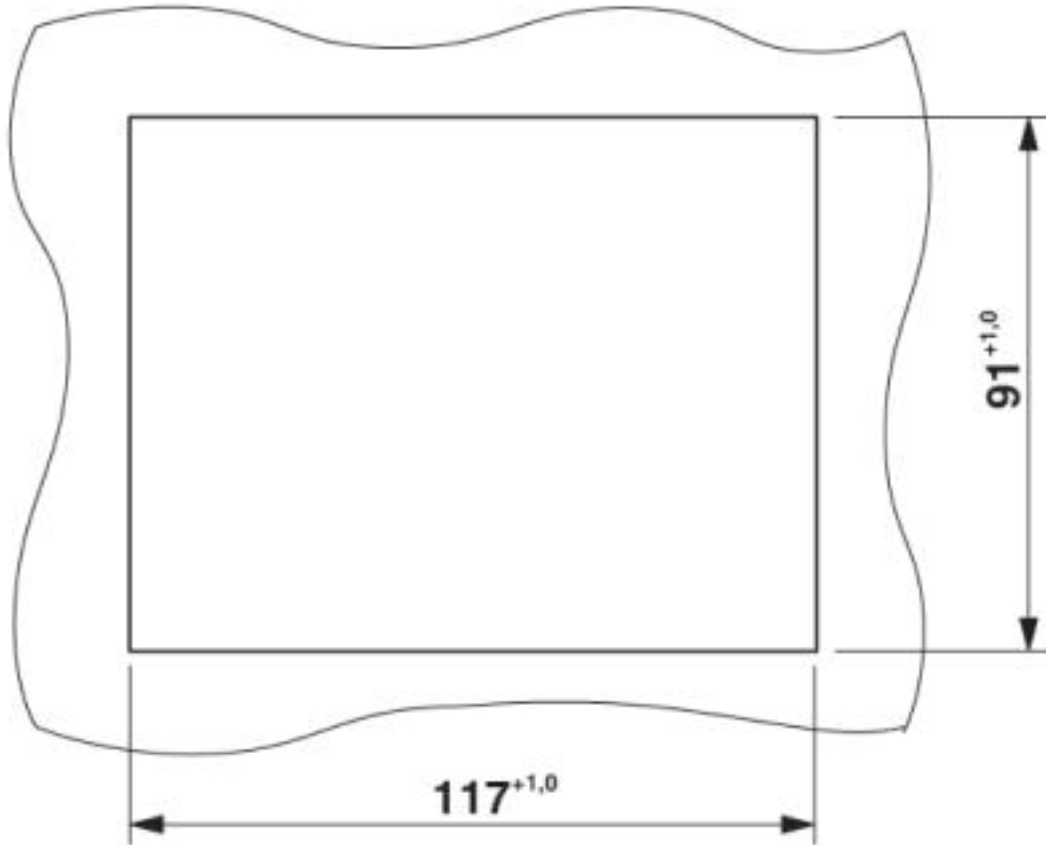

Mounting cutout

## Classifications

eCl@ss

eCl@ss 4.0	27141200
eCl@ss 4.1	27141200
eCl@ss 5.0	27144000
eCl@ss 5.1	27144000
eCl@ss 6.0	27144000
eCl@ss 7.0	27144001
eCl@ss 8.0	27144001
eCl@ss 9.0	27189217

ETIM

ETIM 2.0	EC000007
ETIM 3.0	EC000007
ETIM 4.0	EC000007
ETIM 5.0	EC000007

# Mounting frame - VS-SI-EB-EMV-2 - 1656495

## Classifications

### ETIM

ETIM 6.0	EC000456
ETIM 7.0	EC000456

### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501
UNSPSC 18.0	39121302
UNSPSC 19.0	39121302
UNSPSC 20.0	39121302
UNSPSC 21.0	39121302

## Accessories

### Accessories

#### Data front plate

Front plate - VS-SI-FP-2RJ-MOD - 1656631



Front plate, plastic with shroud, for 2x RJ with modular system (Keystone)

Front plate - VS-SI-FP-2DSUB9 - 1656563



Data front plate, plastic, for 2 x 9-pos. D-SUB, item 1656961 may be required for mounting D-SUB inserts

Front plate - VS-SI-FP-DSUB9-DSUB15 - 1656576



Data front plate, plastic, for 1 x 15-pos. D-SUB and 1 x 15-pos. D-SUB, item 1656961 may be required for mounting D-SUB inserts

## Mounting frame - VS-SI-EB-EMV-2 - 1656495

### Accessories

Front plate - VS-SI-FP-DSUB9-DSUB25 - 1656589



Data front plate, plastic, for 1 x 9-pos. D-SUB and 1 x 25-pos. D-SUB, item 1656961 may be required for mounting D-SUB inserts

---

Front plate - VS-SI-FP-2DSUB15 - 1656592



Data front plate, plastic, for 2 x 15-pos. D-SUB, item 1656961 may be required for mounting D-SUB inserts

---

Front plate - VS-SI-FP-DSUB15-DSUB25 - 1656602



Data front plate, plastic, for 1 x 15-pos. D-SUB and 1 x 25-pos. D-SUB, item 1656961 may be required for mounting D-SUB inserts

---

Front plate - VS-SI-FP-2DSUB25 - 1656615



Data front plate, plastic, for 2x D-SUB 25, item 1656961 may be required for mounting D-SUB inserts

---

### Marking material

Marker labels - VS-SI-BZ - 1656660



Marker label, plastic, plate with 20 labels

---

### Socket

## Mounting frame - VS-SI-EB-EMV-2 - 1656495

### Accessories

Socket insert - VS-SI-SD-DE - 1656505



Ground contact socket, plastic, for Germany

---

Socket insert - VS-SI-SD-DE-G - 1656518



Socket insert, degree of protection: IP20, material: PA, connection method: Screw connection, Germany

---

Socket insert - VS-SI-SD-USA - 1656521



Ground contact socket, plastic, for USA

---

Socket insert - VS-SI-SD-FR - 1656534



Ground contact socket, plastic, for France

---

Socket insert - VS-SI-SD-GB - 1656547



Ground contact socket, plastic, for Great Britain

---

## Mounting frame - VS-SI-EB-EMV-2 - 1656495

### Accessories

Socket insert - VS-SI-SD-IT - 1656550



Socket insert, degree of protection: IP20, material: PA, connection method: Screw connection, color: light gray, Italy

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>