


Marker for terminal blocks - UCT1U-TM 5 - 0803204

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

UniCard materials for thermal transfer printers, for marking terminal blocks from Weidmüller, Conta Clip, and Klemsan, 72-section, offset foot, can be marked with THERMOMARK CARD and BLUEMARK, color: white



Key Commercial Data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 055626 010991
GTIN	4055626010991
Weight per Piece (excluding packing)	13.000 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Dimensions

Length (b)	10 mm
Width (a)	5 mm
Unit of measurement	6 m

Ambient conditions

Ambient temperature (operation)	-40 °C ... 120 °C
Recommended storage conditions	23 °C/50 % relative humidity. Storage in a dry and dark place in the original packaging is recommended.

General

Note	Can be labeled via thermal transfer
Color	white
Type	high
Components	free from silicone, halogen, and cadmium
Flammability rating according to UL 94	V0

Marker for terminal blocks - UCT1U-TM 5 - 0803204

Technical data

General

Material	PC
RoHS compliant	Yes
Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
Number of individual labels	72
Number of individual labels per row	12
Test for substances that would hinder coating with paint or varnish	VW PV 3.10.7:2005-02
Result	Test passed
Test specification weathering-resistance	Following ISO 4892-2:2013-03
Test duration	96 h
Result of weather resistance test	Test passed
Salt spray test specification	DIN EN 60068-2-11:2000-02
Test duration	96 h
Salt spray testing result	Test passed
Wipe resistance of test specification inscriptions	DIN EN 61010-1 (VDE 0411-1):2011-07
Result of wipe resistance test	Test passed
Marking mounting type	clip on
Result	Test passed
Oxygen index (DIN EN ISO 4589-2)	32.4 %
R22	HL 1 - HL 3
R23	HL 1 - HL 3
R24	HL 1 - HL 3


Standards and Regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
Flammability rating according to UL 94	V0

Drawings

Marker for terminal blocks - UCT1U-TM 5 - 0803204

Pictogram

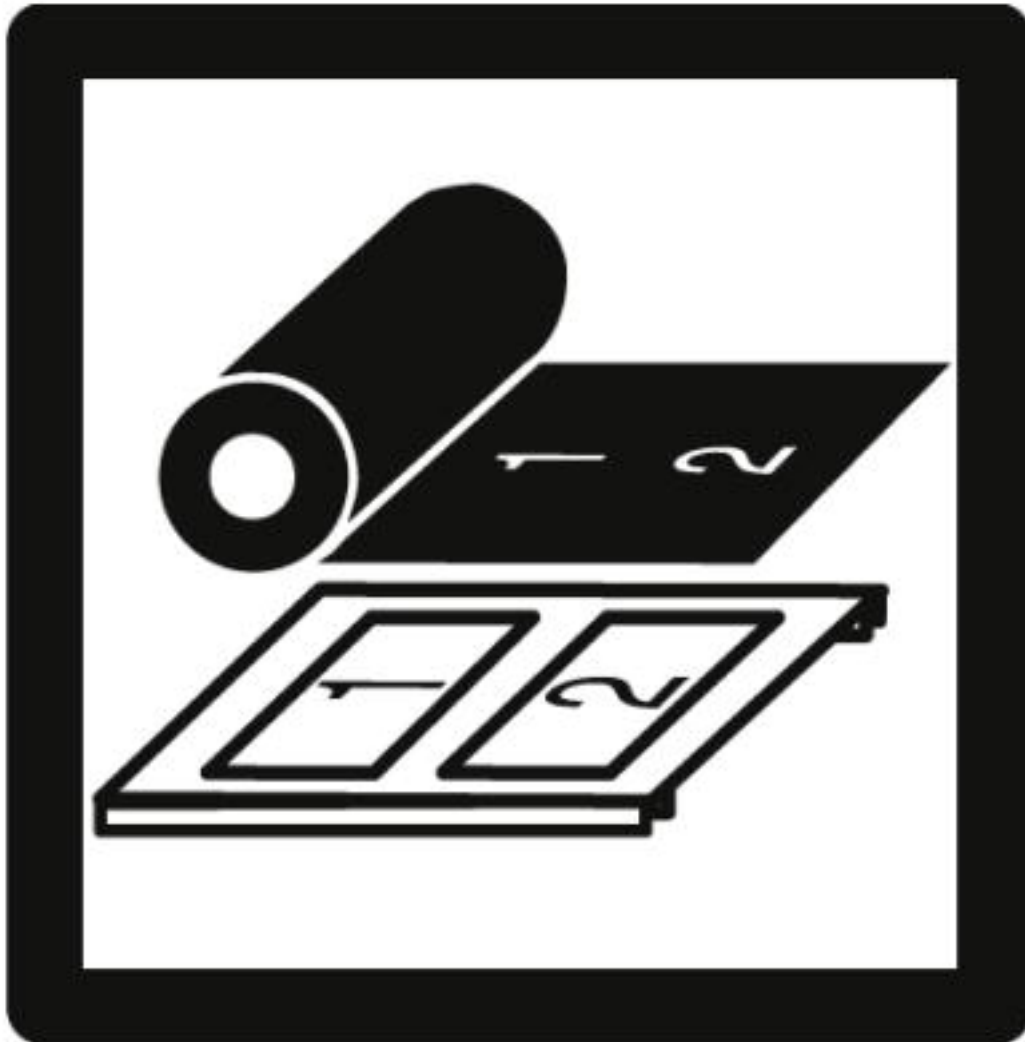

Classifications

eCl@ss

eCl@ss 5.0	27141100
eCl@ss 5.1	27141100
eCl@ss 6.0	27141100
eCl@ss 7.0	27141137
eCl@ss 8.0	27141137
eCl@ss 9.0	27141137

ETIM

ETIM 5.0	EC000761
ETIM 6.0	EC000761

Marker for terminal blocks - UCT1U-TM 5 - 0803204

Classifications

ETIM

ETIM 7.0	EC000761
----------	----------

UNSPSC

UNSPSC 13.2	39131505
UNSPSC 18.0	39131505
UNSPSC 19.0	39131505
UNSPSC 20.0	39131505
UNSPSC 21.0	39131505

Accessories

Accessories

Magazine

Magazine - TMP-UCT-MAG1 - 0803342



Magazine, for the THERMOMARK PRIME and the THERMOMARK CARD, for accommodating UCT-TM..., UCT1(U)-TM..., UCT5-TM..., UCT-EM (5x10), UCT-EM (6x10)