

## Cable duct - CD-HF 25X40 BU - 3240583


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable duct for installation and mounting in control cabinets, blue, halogen-free, comprising upper part and mounting base, width: 25 mm, height: 40 mm, length: 2000 mm



### Key Commercial Data

Packing unit	24 pc
Minimum order quantity	24 pc
GTIN	 4 046356 630016
GTIN	4046356630016
Weight per Piece (excluding packing)	366.000 g
Custom tariff number	39259020
Country of origin	Germany
Note	Made to Order (non-returnable)

### Technical data

#### Dimensions

Length (b)	2000 mm
Width (a)	25 mm
Height (c)	40 mm

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 90 °C
---------------------------------	------------------

#### General

Color	blue
Components	halogen-free
Flammability rating according to UL 94	V0
Material	PC/ABS
Nominal cross section	462 mm <sup>2</sup>

# Cable duct - CD-HF 25X40 BU - 3240583

## Technical data

### Standards and Regulations


Connection in acc. with standard	CSA
Flammability rating according to UL 94	V0

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

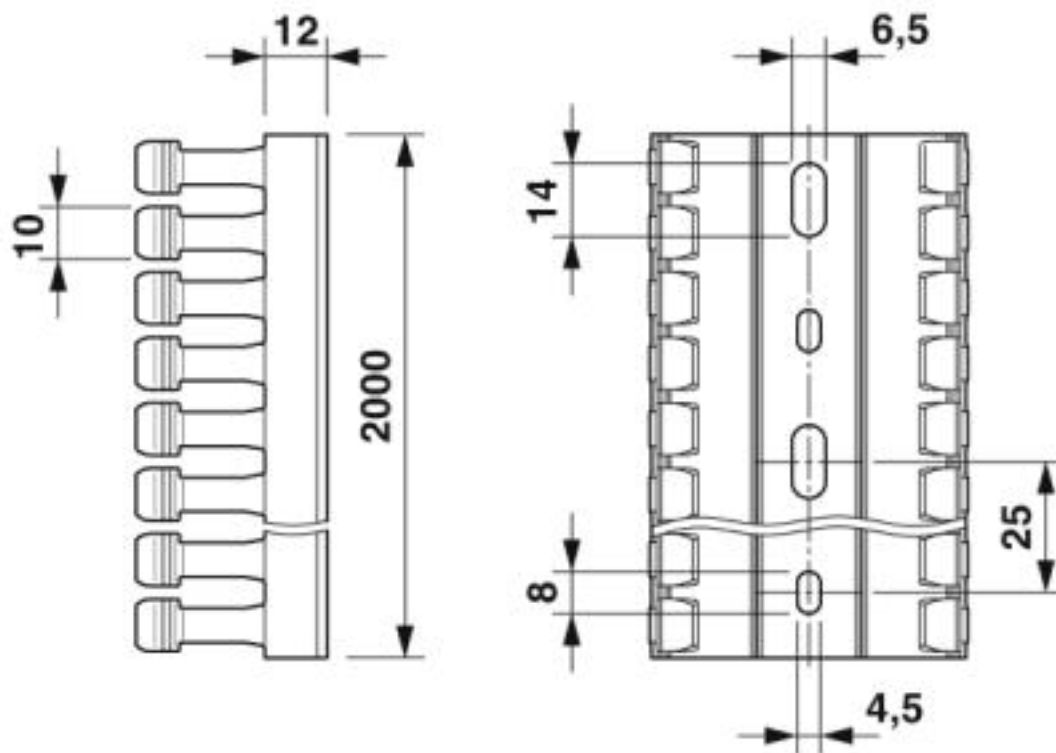

Base perforation according to DIN EN 50085

## Classifications

eCl@ss

eCl@ss 4.0	27140600
eCl@ss 4.1	27140600
eCl@ss 5.0	27140600
eCl@ss 5.1	27140600
eCl@ss 6.0	27400700
eCl@ss 7.0	27400703

# Cable duct - CD-HF 25X40 BU - 3240583

## Classifications

### eCl@ss

eCl@ss 8.0	27400703
eCl@ss 9.0	27400703

### ETIM

ETIM 4.0	EC000012
ETIM 5.0	EC000012
ETIM 6.0	EC000012
ETIM 7.0	EC000012

### UNSPSC

UNSPSC 6.01	30101815
UNSPSC 7.0901	30101815
UNSPSC 11	30101815
UNSPSC 12.01	30101815
UNSPSC 13.2	39131712
UNSPSC 18.0	39131712
UNSPSC 19.0	39131712
UNSPSC 20.0	39131712
UNSPSC 21.0	39131712

## Approvals

### Approvals


#### Approvals

CSA / VDE Zeichengenehmigung

#### Ex Approvals

### Approval details

CSA		<a href="http://www.csagroup.org/services-industries/product-listing/">http://www.csagroup.org/services-industries/product-listing/</a>	248269
-----	---	---	--------

VDE Zeichengenehmigung		<a href="http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx">http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx</a>	40028972
------------------------	---	---	----------

## Cable duct - CD-HF 25X40 BU - 3240583

### Accessories

#### Accessories

#### Filler plug

Fastening clip - RVT-PA 4 - 3240498



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

---

Fastening clip - RVT-PA 6 - 3240499



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

---

#### Riveting tools

Tool - UNIFOX-RVT P 4 - 1212478



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

---

Tool - UNIFOX-RVT P 6 - 1212509



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

---