


PRODUCT-DETAILS

XT4 P FP 4p EF

XT4 P FP 4p EF

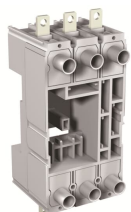

General Information

Extended Product Type	XT4 P FP 4p EF
Product ID	1SDA068198R1
EAN	8015644020941
Catalog Description	XT4 P FP 4p EF
Long Description	FIXED PART PLUG-IN FOR C.BREAKER TMAX FOUR-POLE WITH EXTENDED FRONT TERMINALS XT4

Ordering

E-Number (Sweden)	3182055
EAN	8015644020941
Minimum Order Quantity	1 piece
Customs Tariff Number	85389099

Dimensions

Product Net Width	145 mm
Product Net Height	155 mm
Product Net Depth / Length	295 mm
Product Net Weight	1.270 kg

Container Information

Package Level 1 Units	1 piece
Package Level 1 Width	145 mm
Package Level 1 Height	155 mm
Package Level 1 Depth / Length	295 mm
Package Level 1 Gross Weight	1.42 kg
Package Level 1 EAN	8015644020941

Additional Information

Configuration Type	Loose or configurable
Number of Poles	4
Order Multiple	1 piece
Product Main Type	Accessories for Tmax XT
Product Name	Accessory
Product Type	FP
Rated Frequency (f)	50 / 60 Hz
Rated Impulse Withstand Voltage (U _{imp})	8 kV
Rated Insulation Voltage (U _i)	1000 V
Rated Operational Voltage	690 V AC 500 V DC
Standards	IEC 60947
Sub-type	XT4
Suitable For	XT4
Terminal Connection Type	Plug-In Circuit-Breakers Front Extended
Version	P

Certificates and Declarations (Document Number)

Data Sheet, Technical Information	1SDC210100D0204 1SDC210099D0204
Instructions and Manuals	1SDH000722R0002

Classifications

ETIM 6	EC002043 - Chassis part power circuit breaker
ETIM 7	EC002043 - Chassis part power circuit breaker
Object Classification Code	Q
UNSPSC	39120000
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)

Categories

Low Voltage Products and Systems → Circuit Breakers → Moulded Case Circuit Breakers → Tmax XT

