

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2045320901

Status:


Active

Overview:

Micro-Lock Plus Wire-to-Board Connector System

Description:

Micro-Lock Plus Receptacle Housing, 1.25mm Pitch, Single Row, with Positive Lock, 9 Circuits, Low-Halogen, Black

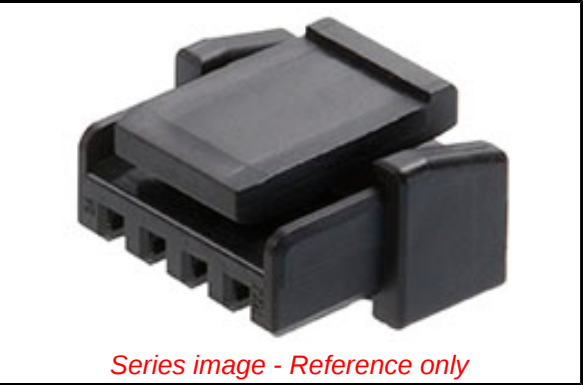

Documents:	
3D Model	Product Specification 2045320001-PS-000 (PDF)
Drawing (PDF)	Application Specification AS-505565-001-001 (PDF)
3D Model (PDF)	Packaging Specification 2045329200-200 (PDF)
Product Specification 2045320000-PS-000 (PDF)	Datasheet (PDF)
Product Specification 2045320000-PS-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	204532
Application	Signal, Wire-to-Board
Overview	Micro-Lock Plus Wire-to-Board Connector System
Product Name	Micro-Lock Plus
UPC	191128418379
Physical	
Circuits (maximum)	9
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	165.679/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-505565-001-001
Packaging Specification	2045329200-200
Product Specification	2045320000-PS-000, 2045320000-PS-001, 2045320001-PS-000
Sales Drawing	2045320000-SD-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ECHA_01_2020 (16 January 2020	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
204532 Series

Mates With
Micro-Lock Plus Header 205957

Use With
Micro-Lock Plus Terminal 505431

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION