

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0369240403](#)  
**Status:** **Active**  
**Overview:** [Mini-Fit Sr. Power Connectors](#)  
**Description:** Mini-Fit Sr.-to-Mini-Fit Sr. Off-the-Shelf (OTS) Cable Assembly, 10.00mm Pitch, Single Row, 0.30m Length, 4 Circuits, Black

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">36924</a>
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Comments	Terminal Position Assurance (TPA) Clip Included, Terminal Position Assurance (TPA) Clip Included
Connector to Connector	Mini-Fit Sr.-to-Mini-Fit Sr.
Overmolded	No
Overview	<a href="#">Mini-Fit Sr. Power Connectors</a>
Product Name	Mini-Fit Sr.
Type	Discrete Wire Assembly
UPC	193264249794

**Physical**

Cable Length	0.30m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	169.350/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	10.00mm
Plating min - Mating	0.762µm
Plating min - Termination	2.540µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	6.60mm max.
Wire Size AWG	8
Wire/Cable Type	UL 1015


**Electrical**

Current - Maximum per Contact	50.0A
-------------------------------	-------

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	369240400-000
---------------	---------------

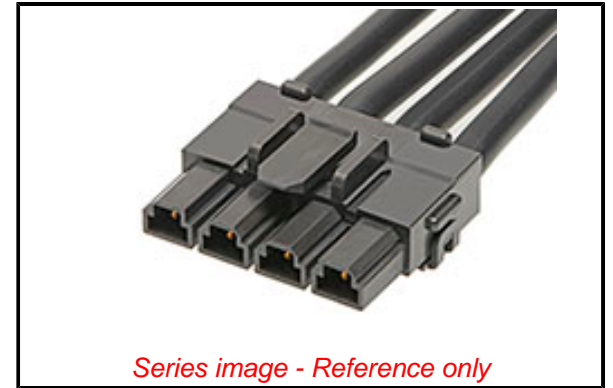

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ECHA\_01\_2020 (16  
January 2020

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[36924 Series](#)

**Mates With**

4 Circuit Plug Housing [428180412](#) , [42819](#)  
<br> 4 Circuit Right-Angle Headers, [42820](#)

**Use With**

Terminal Position Assurance (TPA) Clip  
Included. [42815](#) Female Crimp Terminal