

Flat Flexible Cables - 0.5mm Pitch **multicomp**PRO

**RoHS
Compliant**

Materials

- Insulator : PET(White)
- Support Tape : PET(Blue)
- Contact : Brass Tin Plating


Recommended storage conditions

- Temp : 15°C to 25°C
- Humidity : 30RH% to 60RH%


Length Tolerance

30mm to 50mm $\pm$ 3%, 51mm to 200mm $\pm$ 5%

Dimensions	
Type "1"	Type "2"
S1=3 $\pm$ 1	S1=4 $\pm$ 1
S2=3 $\pm$ 1	S2=4 $\pm$ 1
D1=6 $\pm$ 1	D1=8 $\pm$ 2
D2=6 $\pm$ 1	D2=8 $\pm$ 2

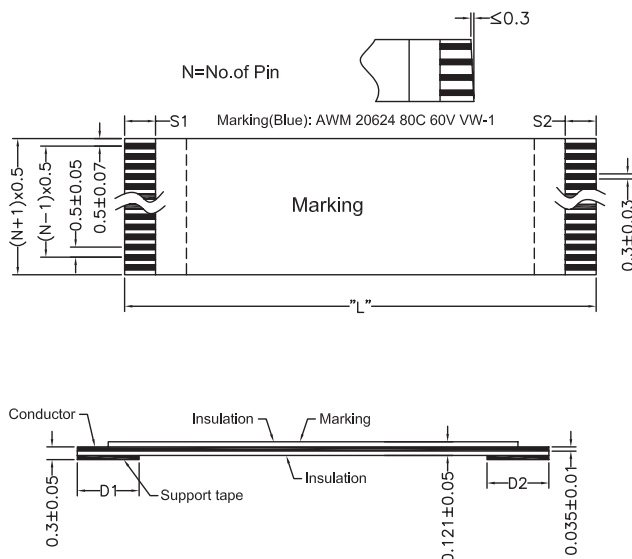

Style A

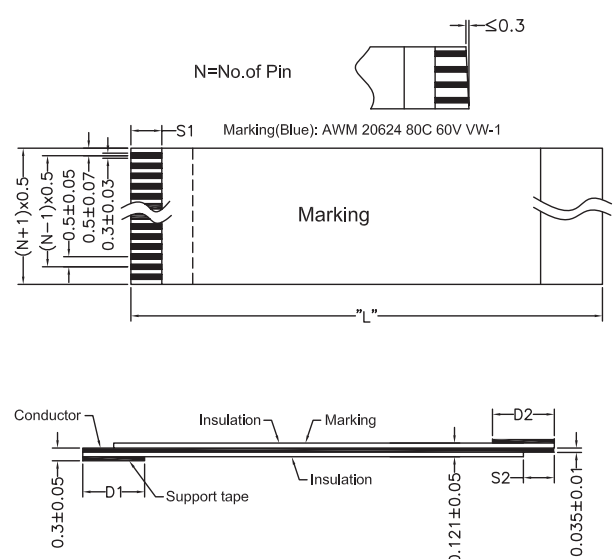

Style B

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicompPRO

Flat Flexible Cables - 0.5mm Pitch **multicomp**PRO

Part Number Table

Description	Part Number
FFC Cable, 6 Way, 50mm, Type 2, Style A	MP-FFCA05060502A
FFC Cable, 6 Way, 50mm, Type 2, Style B	MP-FFCA05060502B
FFC Cable, 6 Way, 100mm, Type 2, Style A	MP-FFCA05061002A
FFC Cable, 6 Way, 100mm, Type 2, Style B	MP-FFCA05061002B
FFC Cable, 6 Way, 152mm, Type 2, Style A	MP-FFCA05061522A
FFC Cable, 6 Way, 152mm, Type 2, Style B	MP-FFCA05061522B
FFC Cable, 6 Way, 200mm, Type 2, Style A	MP-FFCA05062002A
FFC Cable, 6 Way, 200mm, Type 2, Style B	MP-FFCA05062002B
FFC Cable, 8 Way, 50mm, Type 2, Style A	MP-FFCA05080502A
FFC Cable, 8 Way, 50mm, Type 2, Style B	MP-FFCA05080502B
FFC Cable, 8 Way, 100mm, Type 2, Style A	MP-FFCA05081002A
FFC Cable, 8 Way, 100mm, Type 2, Style B	MP-FFCA05081002B
FFC Cable, 8 Way, 152mm, Type 2, Style A	MP-FFCA05081522A
FFC Cable, 8 Way, 152mm, Type 2, Style B	MP-FFCA05081522B
FFC Cable, 8 Way, 200mm, Type 2, Style A	MP-FFCA05082002A
FFC Cable, 8 Way, 200mm, Type 2, Style B	MP-FFCA05082002B
FFC Cable, 10 Way, 50mm, Type 2, Style A	MP-FFCA05100502A
FFC Cable, 10 Way, 50mm, Type 2, Style B	MP-FFCA05100502B
FFC Cable, 10 Way, 100mm, Type 2, Style A	MP-FFCA05101002A
FFC Cable, 10 Way, 100mm, Type 2, Style B	MP-FFCA05101002B
FFC Cable, 10 Way, 152mm, Type 2, Style A	MP-FFCA05101522A
FFC Cable, 10 Way, 152mm, Type 2, Style B	MP-FFCA05101522B
FFC Cable, 10 Way, 200mm, Type 2, Style A	MP-FFCA05102002A
FFC Cable, 10 Way, 200mm, Type 2, Style B	MP-FFCA05102002B
FFC Cable, 12 Way, 50mm, Type 2, Style A	MP-FFCA05120502A
FFC Cable, 12 Way, 50mm, Type 2, Style B	MP-FFCA05120502B
FFC Cable, 12 Way, 51mm, Type 1, Style A	MP-FFCA05120511A
FFC Cable, 12 Way, 100mm, Type 2, Style A	MP-FFCA05121002A
FFC Cable, 12 Way, 100mm, Type 2, Style B	MP-FFCA05121002B
FFC Cable, 12 Way, 152mm, Type 1, Style A	MP-FFCA05121521A
FFC Cable, 12 Way, 152mm, Type 2, Style A	MP-FFCA05121522A
FFC Cable, 12 Way, 152mm, Type 2, Style B	MP-FFCA05121522B
FFC Cable, 12 Way, 200mm, Type 2, Style A	MP-FFCA05122002A
FFC Cable, 12 Way, 200mm, Type 2, Style B	MP-FFCA05122002B
FFC Cable, 14 Way, 50mm, Type 2, Style A	MP-FFCA05140502A
FFC Cable, 14 Way, 50mm, Type 2, Style B	MP-FFCA05140502B

Flat Flexible Cables - 0.5mm Pitch **multicomp**^{PRO}

Description	Part Number
FFC Cable, 14 Way, 100mm, Type 2, Style A	MP-FFCA05141002A
FFC Cable, 14 Way, 100mm, Type 2, Style B	MP-FFCA05141002B
FFC Cable, 14 Way, 152mm, Type 2, Style A	MP-FFCA05141522A
FFC Cable, 14 Way, 152mm, Type 2, Style B	MP-FFCA05141522B
FFC Cable, 16 Way, 50mm, Type 2, Style A	MP-FFCA05160502A
FFC Cable, 16 Way, 50mm, Type 2, Style B	MP-FFCA05160502B
FFC Cable, 16 Way, 100mm, Type 2, Style A	MP-FFCA05161002A
FFC Cable, 16 Way, 100mm, Type 2, Style B	MP-FFCA05161002B
FFC Cable, 16 Way, 152mm, Type 2, Style A	MP-FFCA05161522A
FFC Cable, 16 Way, 152mm, Type 2, Style B	MP-FFCA05161522B
FFC Cable, 16 Way, 200mm, Type 2, Style A	MP-FFCA05162002A
FFC Cable, 18 Way, 50mm, Type 2, Style A	MP-FFCA05180502A
FFC Cable, 18 Way, 100mm, Type 2, Style A	MP-FFCA05181002A
FFC Cable, 20 Way, 50mm, Type 2, Style A	MP-FFCA05200502A
FFC Cable, 20 Way, 50mm, Type 2, Style B	MP-FFCA05200502B
FFC Cable, 20 Way, 51mm, Type 1, Style A	MP-FFCA05200511A
FFC Cable, 20 Way, 100mm, Type 2, Style A	MP-FFCA05201002A
FFC Cable, 20 Way, 100mm, Type 2, Style B	MP-FFCA05201002B
FFC Cable, 20 Way, 152mm, Type 1, Style A	MP-FFCA05201521A
FFC Cable, 20 Way, 152mm, Type 2, Style A	MP-FFCA05201522A
FFC Cable, 20 Way, 152mm, Type 2, Style B	MP-FFCA05201522B
FFC Cable, 20 Way, 200mm, Type 2, Style A	MP-FFCA05202002A
FFC Cable, 20 Way, 200mm, Type 2, Style B	MP-FFCA05202002B
FFC Cable, 22 Way, 50mm, Type 2, Style A	MP-FFCA05220502A
FFC Cable, 22 Way, 50mm, Type 2, Style B	MP-FFCA05220502B
FFC Cable, 22 Way, 200mm, Type 2, Style A	MP-FFCA05222002A
FFC Cable, 22 Way, 200mm, Type 2, Style B	MP-FFCA05222002B
FFC Cable, 24 Way, 50mm, Type 2, Style A	MP-FFCA05240502A
FFC Cable, 24 Way, 50mm, Type 2, Style B	MP-FFCA05240502B
FFC Cable, 24 Way, 100mm, Type 2, Style A	MP-FFCA05241002A
FFC Cable, 24 Way, 100mm, Type 2, Style B	MP-FFCA05241002B
FFC Cable, 24 Way, 152mm, Type 2, Style A	MP-FFCA05241522A
FFC Cable, 24 Way, 152mm, Type 2, Style B	MP-FFCA05241522B
FFC Cable, 24 Way, 200mm, Type 2, Style A	MP-FFCA05242002A
FFC Cable, 24 Way, 200mm, Type 2, Style B	MP-FFCA05242002B
FFC Cable, 26 Way, 152mm, Type 2, Style A	MP-FFCA05261522A
FFC Cable, 26 Way, 152mm, Type 2, Style B	MP-FFCA05261522B

Flat Flexible Cables - 0.5mm Pitch **multicomp**PRO

Description	Part Number
FFC Cable, 26 Way, 200mm, Type 2, Style A	MP-FFCA05262002A
FFC Cable, 28 Way, 50mm, Type 2, Style A	MP-FFCA05280502A
FFC Cable, 28 Way, 100mm, Type 2, Style B	MP-FFCA05281002B
FFC Cable, 30 Way, 50mm, Type 2, Style A	MP-FFCA05300502A
FFC Cable, 30 Way, 50mm, Type 2, Style B	MP-FFCA05300502B
FFC Cable, 30 Way, 51mm, Type 1, Style A	MP-FFCA05300511A
FFC Cable, 30 Way, 100mm, Type 2, Style A	MP-FFCA05301002A
FFC Cable, 30 Way, 100mm, Type 2, Style B	MP-FFCA05301002B
FFC Cable, 30 Way, 152mm, Type 1, Style A	MP-FFCA05301521A
FFC Cable, 30 Way, 152mm, Type 2, Style A	MP-FFCA05301522A
FFC Cable, 30 Way, 152mm, Type 2, Style B	MP-FFCA05301522B
FFC Cable, 30 Way, 200mm, Type 2, Style A	MP-FFCA05302002A
FFC Cable, 30 Way, 200mm, Type 2, Style B	MP-FFCA05302002B
FFC Cable, 32 Way, 127mm, Type 2, Style B	MP-FFCA05321272B
FFC Cable, 32 Way, 152mm, Type 2, Style A	MP-FFCA05321522A
FFC Cable, 32 Way, 200mm, Type 2, Style A	MP-FFCA05322002A
FFC Cable, 32 Way, 200mm, Type 2, Style B	MP-FFCA05322002B
FFC Cable, 33 Way, 100mm, Type 2, Style A	MP-FFCA05331002A
FFC Cable, 33 Way, 152mm, Type 2, Style B	MP-FFCA05331522B
FFC Cable, 33 Way, 200mm, Type 2, Style A	MP-FFCA05332002A
FFC Cable, 33 Way, 200mm, Type 2, Style B	MP-FFCA05332002B
FFC Cable, 34 Way, 152mm, Type 2, Style A	MP-FFCA05341522A
FFC Cable, 35 Way, 50mm, Type 2, Style A	MP-FFCA05350502A
FFC Cable, 40 Way, 50mm, Type 2, Style A	MP-FFCA05400502A
FFC Cable, 40 Way, 50mm, Type 2, Style B	MP-FFCA05400502B
FFC Cable, 40 Way, 51mm, Type 1, Style A	MP-FFCA05400511A
FFC Cable, 40 Way, 76mm, Type 1, Style A	MP-FFCA05400761A
FFC Cable, 40 Way, 100mm, Type 2, Style A	MP-FFCA05401002A
FFC Cable, 40 Way, 100mm, Type 2, Style B	MP-FFCA05401002B
FFC Cable, 40 Way, 102mm, Type 1, Style A	MP-FFCA05401021A
FFC Cable, 40 Way, 152mm, Type 1, Style A	MP-FFCA05401521A
FFC Cable, 40 Way, 152mm, Type 2, Style A	MP-FFCA05401522A
FFC Cable, 40 Way, 152mm, Type 2, Style B	MP-FFCA05401522B
FFC Cable, 40 Way, 200mm, Type 2, Style A	MP-FFCA05402002A
FFC Cable, 40 Way, 200mm, Type 2, Style B	MP-FFCA05402002B
FFC Cable, 45 Way, 50mm, Type 2, Style A	MP-FFCA05450502A
FFC Cable, 45 Way, 50mm, Type 2, Style B	MP-FFCA05450502B
FFC Cable, 45 Way, 100mm, Type 2, Style A	MP-FFCA05451002A
FFC Cable, 45 Way, 152mm, Type 2, Style A	MP-FFCA05451522A

Flat Flexible Cables - 0.5mm Pitch **multicomp**^{PRO}

Description	Part Number
FFC Cable, 45 Way, 200mm, Type 2, Style A	MP-FFCA05452002A
FFC Cable, 45 Way, 200mm, Type 2, Style B	MP-FFCA05452002B
FFC Cable, 50 Way, 50mm, Type 2, Style A	MP-FFCA05500502A
FFC Cable, 50 Way, 50mm, Type 2, Style B	MP-FFCA05500502B
FFC Cable, 50 Way, 100mm, Type 2, Style A	MP-FFCA05501002A
FFC Cable, 50 Way, 100mm, Type 2, Style B	MP-FFCA05501002B
FFC Cable, 50 Way, 152mm, Type 2, Style A	MP-FFCA05501522A
FFC Cable, 50 Way, 152mm, Type 2, Style B	MP-FFCA05501522B
FFC Cable, 50 Way, 200mm, Type 2, Style A	MP-FFCA05502002A
FFC Cable, 50 Way, 200mm, Type 2, Style B	MP-FFCA05502002B

Important Notice : This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp^{PRO}