

RoHS
Compliant

Materials

- Insulator : PET(White)
- Support Tape : PET(Blue)
- Contact : Brass Tin Plating


Recommended storage conditions

- Temp : 15-25°C
- Humidity : 30RH% to 60RH%


Length Tolerance

30mm to 50mm±3, 51mm to 300mm±5, 301mm to 600mm±10

Dimensions	
Type "2"	Type "3"
S1=4±1	S1=5±1
S2=4±1	S2=5±1
D1=8±2	D1=10±2
D2=8±2	D2=10±2

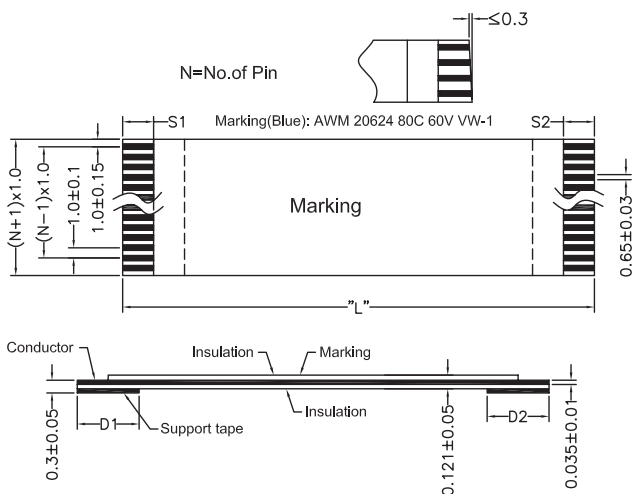

Style A

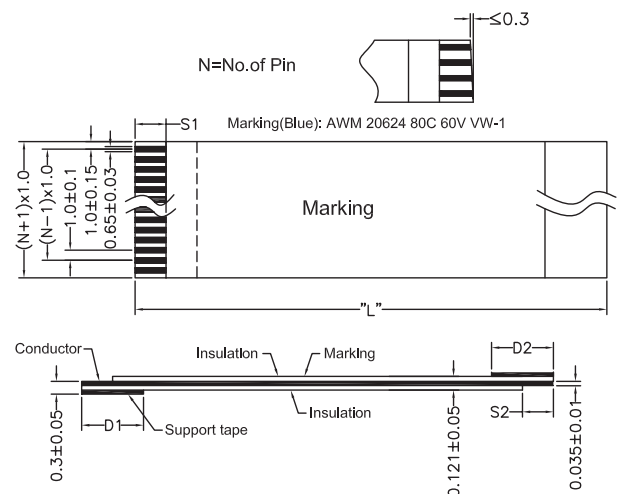

Style B

Part Number Table

Description	Part Number
FFC Cable, 4 Way, 50mm, Type 3, Style A	MP-FFCA10040503A
FFC Cable, 4 Way, 50mm, Type 3, Style B	MP-FFCA10040503B
FFC Cable, 4 Way, 100mm, Type 3, Style A	MP-FFCA10041003A
FFC Cable, 4 Way, 100mm, Type 3, Style B	MP-FFCA10041003B
FFC Cable, 4 Way, 152mm, Type 3, Style A	MP-FFCA10041523A
FFC Cable, 4 Way, 152mm, Type 3, Style B	MP-FFCA10041523B
FFC Cable, 4 Way, 200mm, Type 3, Style A	MP-FFCA10042003A
FFC Cable, 4 Way, 200mm, Type 3, Style B	MP-FFCA10042003B
FFC Cable, 5 Way, 50mm, Type 3, Style A	MP-FFCA10050503A
FFC Cable, 5 Way, 50mm, Type 3, Style B	MP-FFCA10050503B
FFC Cable, 5 Way, 200mm, Type 3, Style A	MP-FFCA10052003A
FFC Cable, 5 Way, 200mm, Type 3, Style B	MP-FFCA10052003B
FFC Cable, 6 Way, 50mm, Type 3, Style A	MP-FFCA10060503A
FFC Cable, 6 Way, 50mm, Type 3, Style B	MP-FFCA10060503B
FFC Cable, 6 Way, 100mm, Type 3, Style A	MP-FFCA10061003A
FFC Cable, 6 Way, 100mm, Type 3, Style B	MP-FFCA10061003B
FFC Cable, 6 Way, 152mm, Type 2, Style A	MP-FFCA10061522A
FFC Cable, 6 Way, 200mm, Type 3, Style A	MP-FFCA10062003A
FFC Cable, 8 Way, 50mm, Type 2, Style A	MP-FFCA10080502A
FFC Cable, 8 Way, 50mm, Type 3, Style B	MP-FFCA10080503B
FFC Cable, 8 Way, 100mm, Type 3, Style A	MP-FFCA10081003A
FFC Cable, 8 Way, 100mm, Type 3, Style B	MP-FFCA10081003B
FFC Cable, 8 Way, 152mm, Type 2, Style A	MP-FFCA10081522A
FFC Cable, 8 Way, 200mm, Type 3, Style A	MP-FFCA10082003A
FFC Cable, 9 Way, 50mm, Type 3, Style B	MP-FFCA10090503B
FFC Cable, 9 Way, 200mm, Type 3, Style A	MP-FFCA10092003A
FFC Cable, 10 Way, 50mm, Type 3, Style A	MP-FFCA10100503A
FFC Cable, 10 Way, 51mm, Type 2, Style A	MP-FFCA10100512A
FFC Cable, 10 Way, 100mm, Type 3, Style A	MP-FFCA10101003A
FFC Cable, 10 Way, 100mm, Type 3, Style B	MP-FFCA10101003B
FFC Cable, 10 Way, 152mm, Type 2, Style A	MP-FFCA10101522A
FFC Cable, 10 Way, 152mm, Type 3, Style A	MP-FFCA10101523A
FFC Cable, 10 Way, 200mm, Type 3, Style B	MP-FFCA10102003B
FFC Cable, 10 Way, 305mm, Type 2, Style A	MP-FFCA10103052A
FFC Cable, 12 Way, 100mm, Type 3, Style A	MP-FFCA10121003A
FFC Cable, 12 Way, 152mm, Type 2, Style A	MP-FFCA10121522A
FFC Cable, 14 Way, 50mm, Type 3, Style A	MP-FFCA10140503A
FFC Cable, 14 Way, 100mm, Type 3, Style A	MP-FFCA10141003A

Flat Flexible Cables - 1mm Pitch



Description	Part Number
FFC Cable, 14 Way, 100mm, Type 3, Style B	MP-FFCA10141003B
FFC Cable, 14 Way, 152mm, Type 2, Style A	MP-FFCA10141522A
FFC Cable, 14 Way, 305mm, Type 2, Style A	MP-FFCA10143052A
FFC Cable, 15 Way, 50mm, Type 3, Style A	MP-FFCA10150503A
FFC Cable, 15 Way, 50mm, Type 3, Style B	MP-FFCA10150503B
FFC Cable, 15 Way, 100mm, Type 3, Style A	MP-FFCA10151003A
FFC Cable, 15 Way, 100mm, Type 3, Style B	MP-FFCA10151003B
FFC Cable, 15 Way, 152mm, Type 3, Style B	MP-FFCA10151523B
FFC Cable, 15 Way, 200mm, Type 3, Style A	MP-FFCA10152003A
FFC Cable, 15 Way, 200mm, Type 3, Style B	MP-FFCA10152003B
FFC Cable, 16 Way, 50mm, Type 3, Style A	MP-FFCA10160503A
FFC Cable, 16 Way, 51mm, Type 2, Style A	MP-FFCA10160512A
FFC Cable, 16 Way, 100mm, Type 3, Style A	MP-FFCA10161003A
FFC Cable, 16 Way, 100mm, Type 3, Style B	MP-FFCA10161003B
FFC Cable, 16 Way, 152mm, Type 2, Style A	MP-FFCA10161522A
FFC Cable, 18 Way, 100mm, Type 3, Style A	MP-FFCA10181003A
FFC Cable, 20 Way, 50mm, Type 3, Style A	MP-FFCA10200503A
FFC Cable, 20 Way, 51mm, Type 2, Style A	MP-FFCA10200512A
FFC Cable, 20 Way, 100mm, Type 3, Style A	MP-FFCA10201003A
FFC Cable, 20 Way, 100mm, Type 3, Style B	MP-FFCA10201003B
FFC Cable, 20 Way, 152mm, Type 2, Style A	MP-FFCA10201522A
FFC Cable, 20 Way, 200mm, Type 3, Style A	MP-FFCA10202003A
FFC Cable, 20 Way, 200mm, Type 3, Style B	MP-FFCA10202003B
FFC Cable, 22 Way, 152mm, Type 2, Style A	MP-FFCA10221522A
FFC Cable, 24 Way, 100mm, Type 3, Style A	MP-FFCA10241003A
FFC Cable, 24 Way, 152mm, Type 2, Style A	MP-FFCA10241522A
FFC Cable, 24 Way, 200mm, Type 3, Style A	MP-FFCA10242003A
FFC Cable, 26 Way, 152mm, Type 2, Style A	MP-FFCA10261522A
FFC Cable, 26 Way, 200mm, Type 3, Style A	MP-FFCA10262003A
FFC Cable, 26 Way, 200mm, Type 3, Style B	MP-FFCA10262003B
FFC Cable, 30 Way, 50mm, Type 3, Style B	MP-FFCA10300503B
FFC Cable, 30 Way, 100mm, Type 3, Style A	MP-FFCA10301003A
FFC Cable, 30 Way, 100mm, Type 3, Style B	MP-FFCA10301003B
FFC Cable, 30 Way, 152mm, Type 2, Style A	MP-FFCA10301522A

Important Notice : This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro
 Farnell.com/multicomp-pro
 Element14.com/multicomp-pro

