


## KR8G5

151-24850

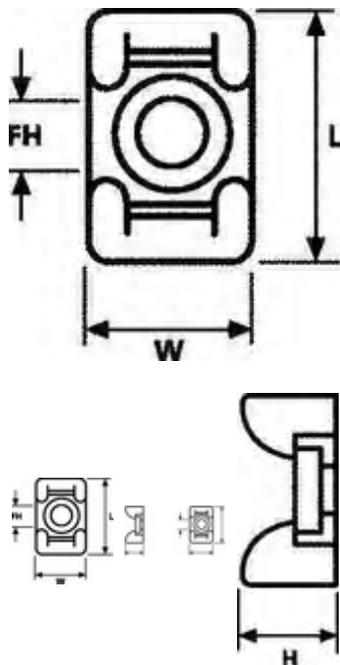

KR mounts give additional support to the cables by means of their curved design. Simple to install with a screw or bolt they give excellent security, particularly in areas of high vibration when used in conjunction with the KR straps. They must offer one of the most vibration resistant fixings available.

Designed specifically for holding heavier cable bundles these mounting bases can be used in many industries from agriculture to truck manufacture, they offer a very secure fixing and can be used with a wide variety of heavy duty cable ties up to 7.6mm wide.

**Base Data****Colour**

Black (BK)

**Package Content**

100

**Quantity (Sold Unit / EDP)**

100

**Logisitic and Packaging****Carton Quantity**

2000

**EAN code**

4031026217468

**Quantity of Europallet**

96000

**Weight (kg) (Metric)**

1.86 kg

**Material and Specifications****Flammability**

UL94 V2

**Material**

Polyamide 6.6 Heat Stabilised (PA66HS)

**Material Shortcut**

PA66HS

**Operating Temperature (Metric)**

-40 °C to +105 °C Continuous, (+145 °C for 500 h)

**ROHS Conformity**

TRUE

**Product Dimensions****Cable Tie Width max. (metric)**

8.0

**Height H (Metric)**

12.0

**Height H2 (Metric)**

5.5

**Hole**

6.5

**Length L (Metric)**

25.0

**Width W (Metric)**

14.5

© HellermannTyton 2006