



## Main

Range	TeSys
Product or component type	Extended rotary handle
Device short name	GV7AP
Range compatibility	TeSys GV7 motor circuit breaker TeSys GV5 motor circuit breaker
Accessory / separate part category	Control accessory
Rotary handle mounting location	Front
Rotary handle mounting style	Extended

## Complementary

Handle colour	Red
Handle front plate colour	Yellow
Back/Door distance	185...600 mm
Rotary handle padlocking	1 to 3 padlocks 5...8 mm Padlock in OFF position
Net weight	0.775 kg

## Environment

IP degree of protection	IP55
-------------------------	------

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a>


Product out of China RoHS scope. Substance declaration for your information

Environmental Disclosure	<a href="#">Product Environmental Profile</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

### Contractual warranty

Warranty	18 months
----------	-----------

Extended Rotary Handle GV7AP01, GV7AP02

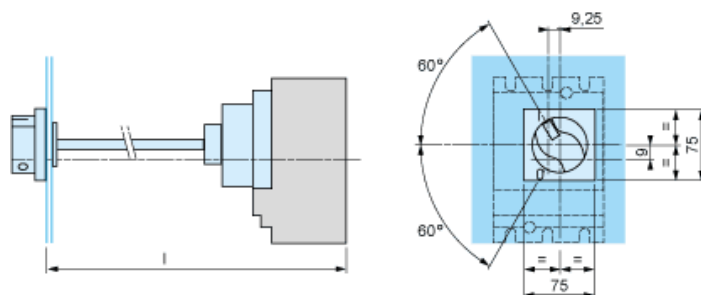

l: 185 minimum, 600 maximum

The shaft of the extended rotary handle GV7AP01 or GV7AP02 must be cut to length:  $l - 126$  mm.