




### Single Mode Timer

- On Delay
- 10 Time Ranges
- Front knobs for Time Range & Time Scale
- Slim, Space Saving Design
- DIN Rail Mount

### SPECIFICATIONS


<b>ACCURACY</b>	Setting: $\pm 5\%$ of F.S. Repeat: $\pm 0.5\%$ (F.S. = Full Scale)
<b>RESET</b>	Reset time < 100 msec
<b>OUTPUT CONTACT</b>	SPDT (1 C/O)
<b>CONTACT RATING</b>	NO/5A, NC/3A @ 250V AC
<b>MODES</b>	On delay (A)
<b>TIME RANGES</b>	0.1 - 1 sec, 0.3 - 3 sec, 1-10 sec, 3-30 sec 0.1-1 min, 0.3-3 min, 1-10 min, 3-30 min 0.1-1 hr, 0.3-3 hr
<b>SUPPLY</b>	110V AC : (50 or 60 Hz)
<b>POWER CONSUMPTION</b>	4.0 VA
<b>TEMPERATURE</b>	Operating: 0 to 50°C (32 to 122°F) Storage: -20 to 75°C (-4 to 167°F)
<b>HUMIDITY (NON-CONDENSING)</b>	95% RH
<b>WEIGHT</b>	2.151 oz.
<b>PROTECTION LEVEL</b>	NEMA 12

### DIMENSIONS (MILLIMETERS)

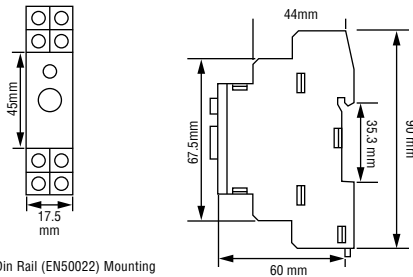


Symmetrical 35mm Din Rail (EN50022) Mounting

### TIMING DIAGRAM

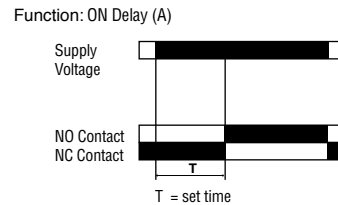

### TERMINAL CONNECTIONS

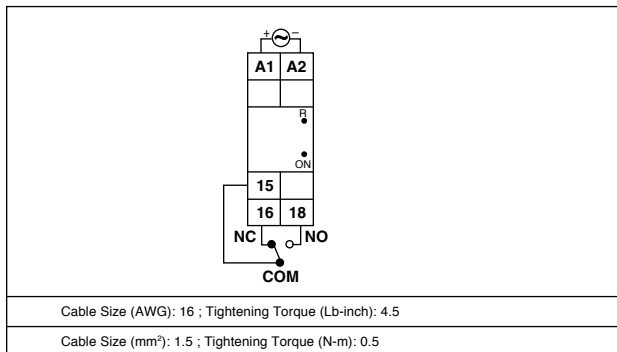

### ORDERING INFORMATION

PART NO.	SUPPLY VOLTAGE
175SO-110	110V AC