


Clevis flange SNC-80

Part number: 174387

FESTO

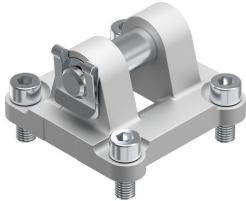

Data sheet

Feature	Value
Size	80
Type code	SNC
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-40 °C ... 150 °C
Product weight	620 g
Note on materials	Free of copper and PTFE RoHS-compliant
Mounting material	Die-cast aluminum
Bolt material	Steel Galvanized
Material of screws	Galvanized Steel
Fuse material	Spring steel Galvanized