


Manifold rail VABM-L1-14W-G14-6-GR

Part number: 573502

FESTO

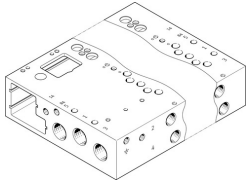

Data sheet

Feature	Value
Width dimension	16 mm
Type code	VABM
Mounting position	Any
Max. no. of valve positions	6
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-20 °C ... 60 °C
Certification	c UL us - Recognized (OL) c CSA us (OL)
Product weight	1041 g
Pilot air port 12/14	M5
Pilot exhaust air port 82/84	M5
Pneumatic connection 1	G1/4
Pneumatic connection 2	G1/8
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/8
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy