

Product Information




Quantity:



Pneumatic Timer 0.3 - 10 min (M/50923)

Features

- Three timing bands allow a range of applications
- Entirely pneumatic - particularly suitable for use in hazardous environments
- Sub-base mounted with bottom ports
- Suitable for panel mounting

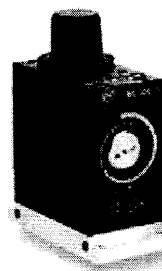

Technical Data

Size:	M5
Timing ranges:	0.3 - 10 min
Operating temperature:	-20°C to +60°C. Consult our technical service for use below +2°C
Mounting:	In-line
Medium:	Compressed air, filtered, lubricated or non-lubricated, inert gases
Operating pressure:	1,5 to 8 bar
Materials:	Plastic body, aluminium sub-base, nitrile rubber seals
Series:	