


ECASD41D476M040KA0



Appearance & Shape

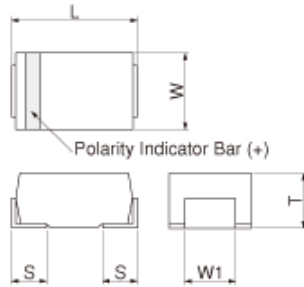

References

Packaging	Specifications	Minimum Order Quantity
K	330Embossed Tape	3000

Mass (typ.)	
1 piece	0.13g

Attention

- This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

ECASD41D476M040KA0

Specifications

Length	7.3±0.3mm
Width	4.3±0.2mm
Thickness	1.9±0.1mm
Allowable Ripple Current	1.8Arms
Capacitance	47μF ±20%
ESR	40mΩ
Leakage Current	282.0μA
Maximum operating temperature	105°C
Operating Temperature Range	-40°C to 105°C
Rated Voltage	20Vdc
Size code in inch (mm)	2917(7343)
S size	1.3±0.2mm
Capacitance change rate	±20%
W1 size	2.4±0.2mm

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.