

A

B

C

D

1





2

3

4

5

6

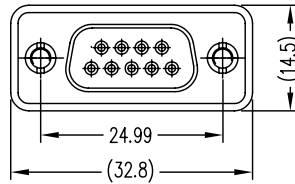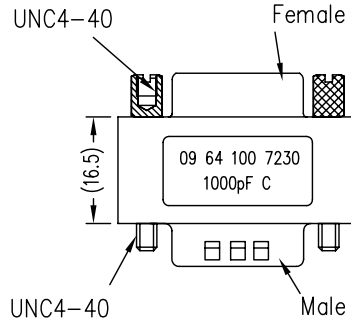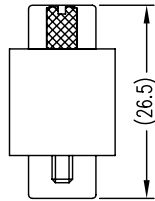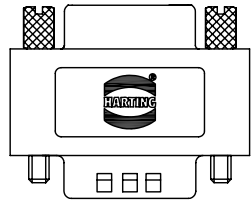

Specification

Filter type	C
Capacitance	1000pf±20%
Working Voltage	100V
Current rating	6.5 A

Minimum Insertion Loss

FREQUENCY (MHz)	ATTENUATION dB
5	1dB
10	3dB
50	12dB
100	20dB
500	34dB
1000	30dB

Notes

Screws are not pre-mounted to allow mounting from any ends

<p>All Dimensions in mm Original Size DIN A 4</p>	Techn. Character.			Free size tolerances	
		Dat.	Name		
	Detail.	03.09.07	J.S.	1:1	
	Insp.	03.09.07	J.S.		
	Stand.				
				Male/Female D-Sub Filter Adapter 9pin, 1000pF	
Mod.	Dat.	Name	Zuhai HARTING Limited	TB 09 64 100 7230	Page
				Sub.	