

1 2 3 4 5 6



A
B
C
D

Specification

Filter type	C
Capacitance	1000pf±20%
Working Voltage	100V
Current rating	6.5 A

Minimum Insertion Loss

FREQUENCY (MHz)	ATTENUATION dB
5	1dB
10	3dB
50	12dB
100	20dB
500	34dB
1000	30dB

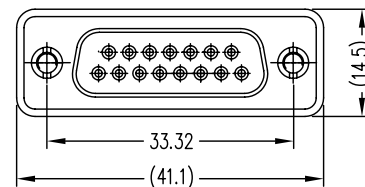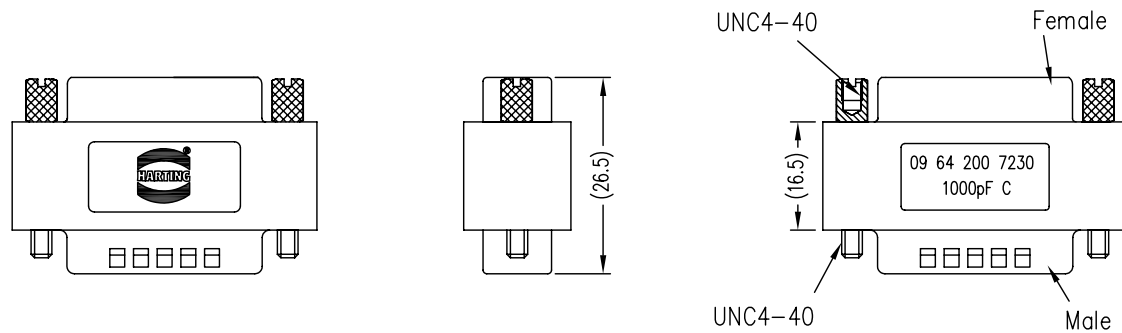

Notes

Screws are not pre-mounted to allow mounting from any ends

All Dimensions in mm Original Size DIN A 4			Techn. Character.			Free size tolerances		
				Dat.	Name	Scale 1:1	Male/Female D-Sub Filter Adapter 15pin, 1000pF	
			Detail.	03.09.07	J.S.			
			Insp.	03.09.07	J.S.			
			Stand.					
Mod.	Dat.	Name	Zhuhai HARTING Limited					TB 09 64 200 7230
						Sub.		Page