


1 2 3 4 5 6

A

B

C

D

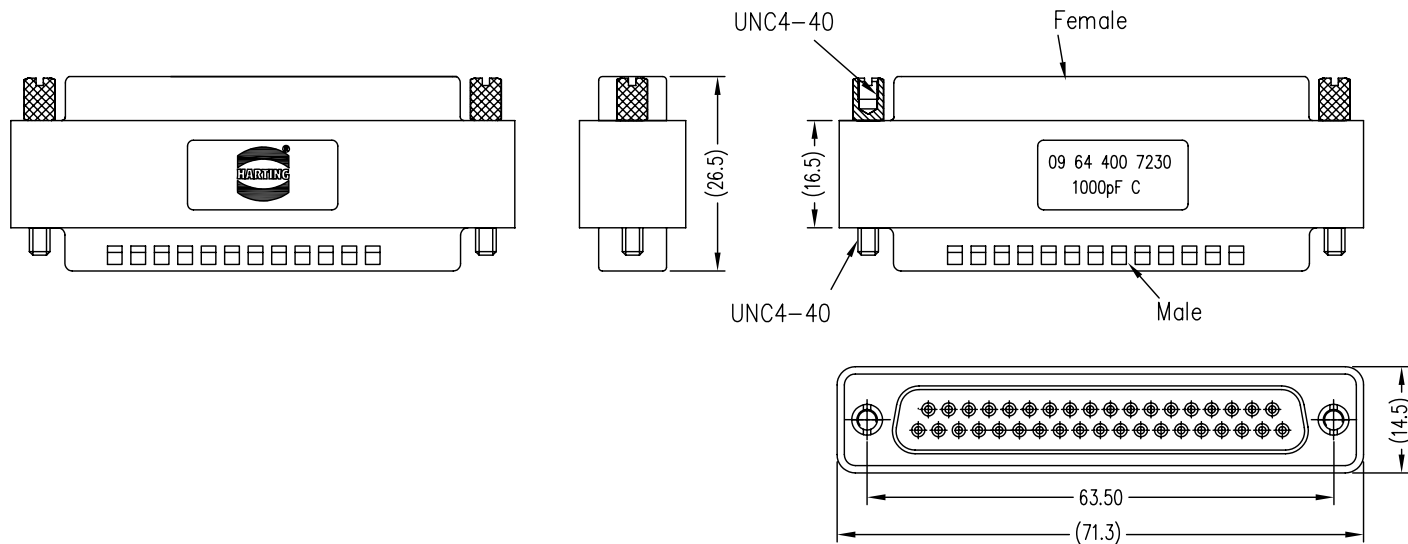

Specification

Filter type	C
Capacitance	1000pf±20%
Working Voltage	100V
Current rating	6.5 A

Minimum Insertion Loss

FREQUENCY (MHz)	ATTENUATION dB
5	1dB
10	3dB
50	12dB
100	20dB
500	34dB
1000	30dB

Notes

Screws are not pre-mounted to allow mounting from any ends

<p>All Dimensions in mm Original Size DIN A 4</p>			Techn. Character.			Free size tolerances		
				Dat.	Name	Scale		Male/Female D-Sub Filter Adapter 37pin, 1000pF
			Detail.	03.09.07	J.S.	1:1		
			Insp.	03.09.07	J.S.			
			Stand.					
				Zhuhai HARTING Limited				
Mod.	Dat.	Name				TB 09 64 400 7230		Page
						Sub.		