


Type	Size	Description	Part No.
Incandescent	T10 (T-3¼)	Miniature Screw lamp (MES ~ 28 MOL)	(see table)

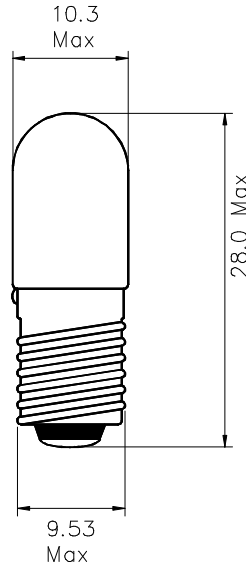

Drawing not to scale
All dimensions in mm

PHOTOMETRY DATA

Farnell Part No.	SLI P/N	Lamp Rating	Test Volts	Current (mA)			Light Output (Lm)			Fil Shape	Life (Hrs)
				Min	Nom	Max	Min	Nom	Max		
328224	W503	6.5V 1.95W	6.5	270	300	330	10	12	14	C-2R	4000
328236	W1309	12V 2.2W	12	165	183	201	8.5	11	13.5	C-2V	3000
620531	W577	12V 3W	12	225	250	275	10	12.5	15	C-2F	4000
328248	W592	24V 1.2W	24	45	50	55	3.0	4.0	5.0	C-2F	5000
328250	W599	24V 2.8W	24	102	120	138	8.4	12	15.6	C-2F	3000
527040	W1122	24V 1.75W	24	65	73	81	3.2	4.5	5.8	C-2F	25000
328261	W607	50V 2.5W	50	45	50	55	6.8	9.0	11.2	CC-2F	5000
620543	W609	60V 3W	60	45	50	55	8	10.5	13	CC-2F	3000
254150	W1159	130V 2.6W	130	18	20	22	2.0	3.0	4.0	CC-4F	3000

NOTES:

- 1) E10/13 nickel-plated screw cap in accordance with IEC 61-1, (BS EN 60061-1), sheet 7004-22-x.
- 2) Metal base to be durably marked with rating and trademark.
- 3) Products rated at 50Vac and above shall conform to European standards and directives SI 1994/3260, 73/23/EEC and 93/68/EEC and display the CE mark on the packaging labels.