

# LA9D40961

Contacteur Cable Connector, For Use With:  
LC1/LP1 D40 thru D65

List Price \$5.50 USD

Availability **Stock Item: This item is normally stocked in our distribution facility.**

## Technical Characteristics

Application	Links for the parallel connection of 2-Pole contactors
Marketing Trade Name	TeSys
Catalog Reference Number	8502CT9901
For Use With	LC1/LP1 D40 thru D65


## Shipping and Ordering

Category	22341 - Contactors, IEC, Accessories, D, K & F-Line
Discount Schedule	I12
Article Number	785901490982
Package Quantity	2
Weight	0.09 lbs.
Availability Code	Stock Item: This item is normally stocked in our distribution facility.
Returnability	N

As standards, specifications, and designs change from time to time, please ask for confirmation of the information given in this document.


# D-line Contactors, Enclosed Starters, Overload Relays, and Accessories

## Selection of Contactors and Reversing Contactors

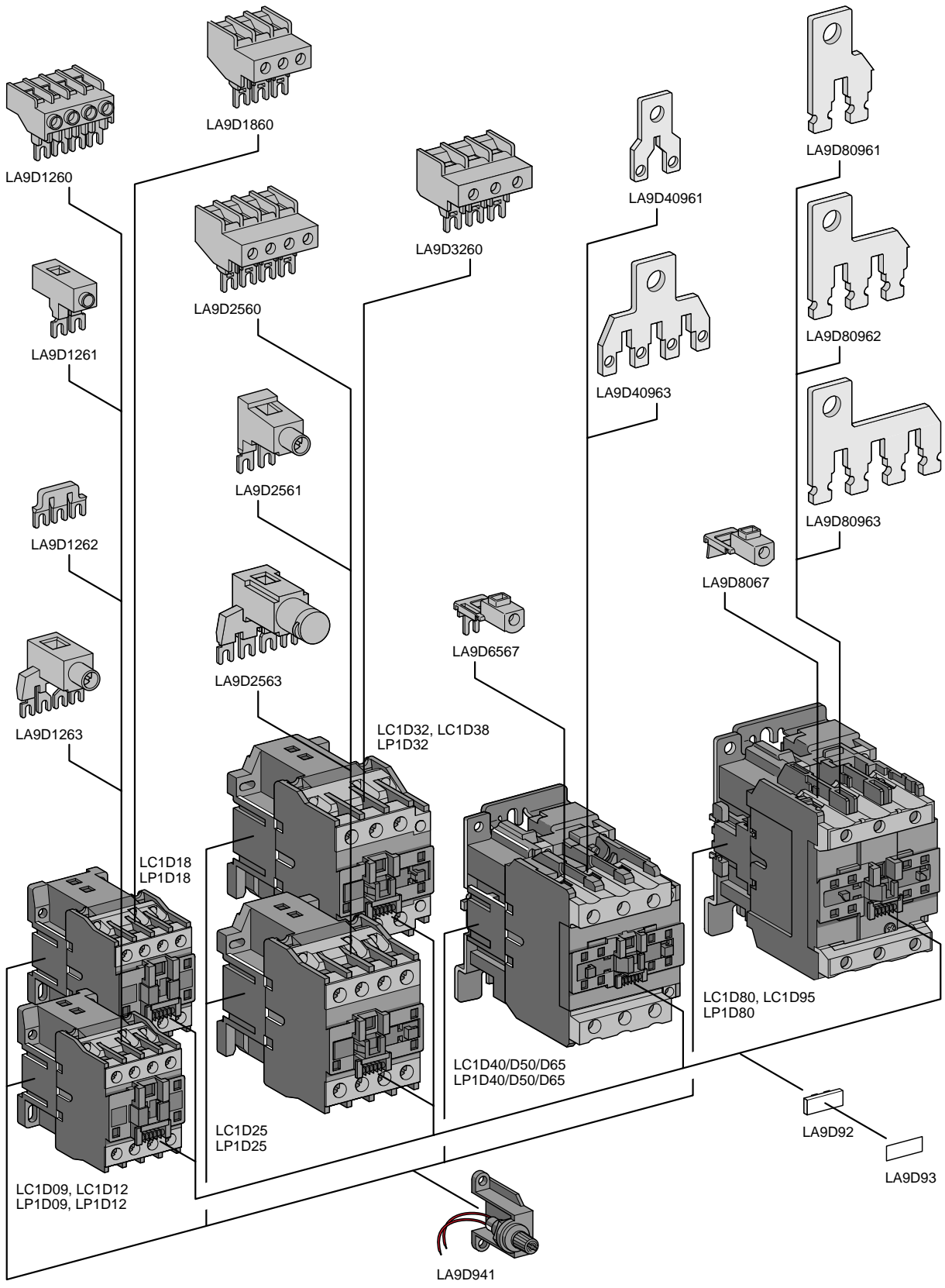


# D-line Contactors, Enclosed Starters, Overload Relays, and Accessories Selection of Contactors and Reversing Contactors


## Types LC•D and LP•D: Accessories for Main Pole and Control Connections

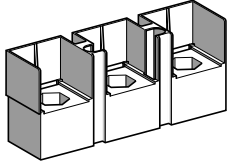


**LA9D11550•**

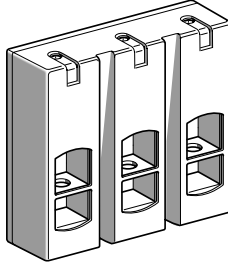


**LA9D11560•**

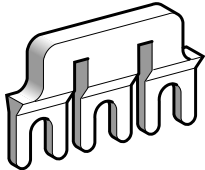


**LA9D1262**

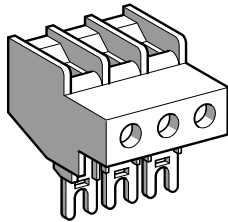

**LA9D1860**

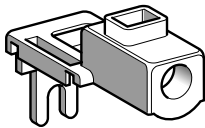

**LA9D6567**

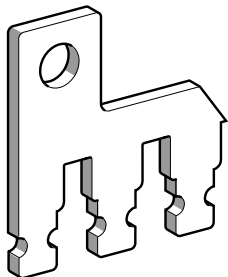

**LA9D80962**

Description		For use on contactors		Sold in lots of	Catalog Number	Weight – kg (lb.)	
		LC1	LP1				
Connectors for larger cable sizes	4-pole 10 mm <sup>2</sup> (#8 AWG)	D09, D12	D09, D12	1	LA9D1260	0.030 (0.066)	
	3-pole 25 mm <sup>2</sup>	D18	D18	1	LA9D1860	0.035 (0.077)	
		D2500 D32, D38	D32	1	LA9D3260	0.040 (0.088)	
	4-pole 25 mm <sup>2</sup> (#4 AWG)	D25	D25	1	LA9D2560	0.050 (0.11)	
IP20 Touch-safe terminals for stranded or solid cable	3-pole 120 mm <sup>2</sup>	D115, D150	D115, D150	1	LA9D115603	0.540 (0.188)	
	4-pole 120 mm <sup>2</sup> (250 MCM)	D115	D115	1	LA9D115604	0.730 (1.606)	
Connectors for ring tongue terminals or bus bar	3-pole	D115, D150	D115, D150	1	LA9D115503	0.230 (0.506)	
	4-pole	D115	D115	1	LA9D115504	0.320 (0.704)	
Links for parallel connection of	2 poles	D09, D12	D09, D12	10	LA9D1261	0.012 (0.046)	
		D25	D25	10	LA9D2561	0.060 (0.132)	
		D40 to D65	D40 to D65	2	LA9D40961	0.021 (0.046)	
		D80, D95	D80	2	LA9D80961	0.060 (0.132)	
	3 poles (Wye Delta shorting strap)	D09, D12	D09, D12	10	LA9D1262	0.003 (0.006)	
		D80, D95	D80	1	LA9D80962	0.080 (0.176)	
	4 poles	D09, D12	D09, D12	2	LA9D1263	0.024 (0.053)	
		D25	D25	2	LA9D2563	0.017 (0.037)	
		D40 to D65	D40 to D65	2	LA9D40963	0.070 (0.154)	
		D80, D95	D80	2	LA9D80963	0.100 (0.22)	
	Staggered coil connection		–	D40 to D80	10	LA9D09966	0.006 (0.013)
	Control circuit take-off from main pole		–	D40 to D65	10	LA9D6567	0.010 (0.022)
D80				10	LA9D8067	0.010 (0.022)	
Spreader allowing direct connection to GV7 manual motor protector ♦		D11500, D15000	D11500, D15000	3	GV7-AC03	0.180 (0.040)	

♦ Increases pole pitch on GV7 to 45mm (1.77 inches).

