

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2070170012

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Sigma Sealed Plug Housing, Dual Row, 4.20mm Pitch, 12 Circuits, UL94V-0, Natural

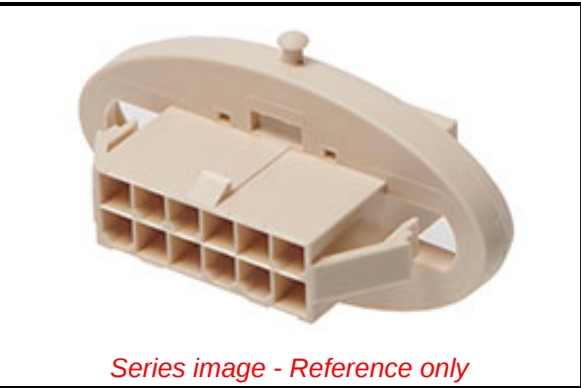

Documents:	
3D Model	Packaging Specification 2070170000-PK-000 (PDF)
Drawing (PDF)	Test Summary 2070170000-TS-000 (PDF)
3D Model (PDF)	Test Summary 2070170001-TS-000 (PDF)
Product Specification 2070170000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 2070170000-AS-000 (PDF)	

General	
Product Family	Crimp Housings
Series	207017
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Sigma
UPC	193264428533
Physical	
Circuits (maximum)	12
Color - Resin	Natural
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	6.850/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	2070170000-AS-000
Packaging Specification	2070170000-PK-000
Product Specification	2070170000-PS-000
Sales Drawing	2070170000-SD-000
Test Summary	2070170000-TS-000, 2070170001-TS-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ECHA_01_2020 (16 January 2020)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207017 Series

Mates With

Mini-Fit Jr. Receptacle Housing [5557](#) , [46992](#) , [172708](#)

Use With

Mini-Fit Sigma Sealed Cap [2070190012](#)

 Mini-Fit TPA2 Male Crimp Terminal [172765](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION