

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2053410205](#)  
**Status:** **Active**  
**Overview:** [Pico-Lock Connector System](#)  
**Description:** 2.00mm Pitch, Pico-Lock Receptacle Crimp Housing, Single Row, Positive Lock, 5 Circuits, Black

**Documents:**

<a href="#">3D Model</a>	<a href="#">Application Specification 2053410000-AS-000 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification 2053419200-SPK-200 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Product Specification 2053410000-PS-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**General**

Product Family	Crimp Housings
Series	<a href="#">205341</a>
Application	Signal, Wire-to-Board
Overview	<a href="#">Pico-Lock Connector System</a>
Product Name	Pico-Lock
UPC	191130510009


**Physical**

Circuits (maximum)	5
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyamide
Net Weight	170.080/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

**Material Info**

**Reference - Drawing Numbers**

Application Specification	2053410000-AS-000
Packaging Specification	2053419200-SPK-200
Product Specification	2053410000-PS-000
Sales Drawing	2053410000-SD-000

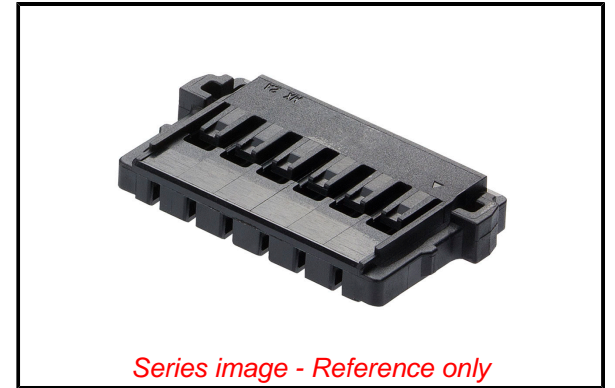

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ECHA\_01\_2020 (16  
January 2020

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[205341 Series](#)

**Mates With**

Pico-Lock PCB Header [205338](#)

**Use With**

Pico-Lock Crimp Terminal [205342](#)