


Rating: 150A DC, 120A AC 0.020" to 3/32" electrodes

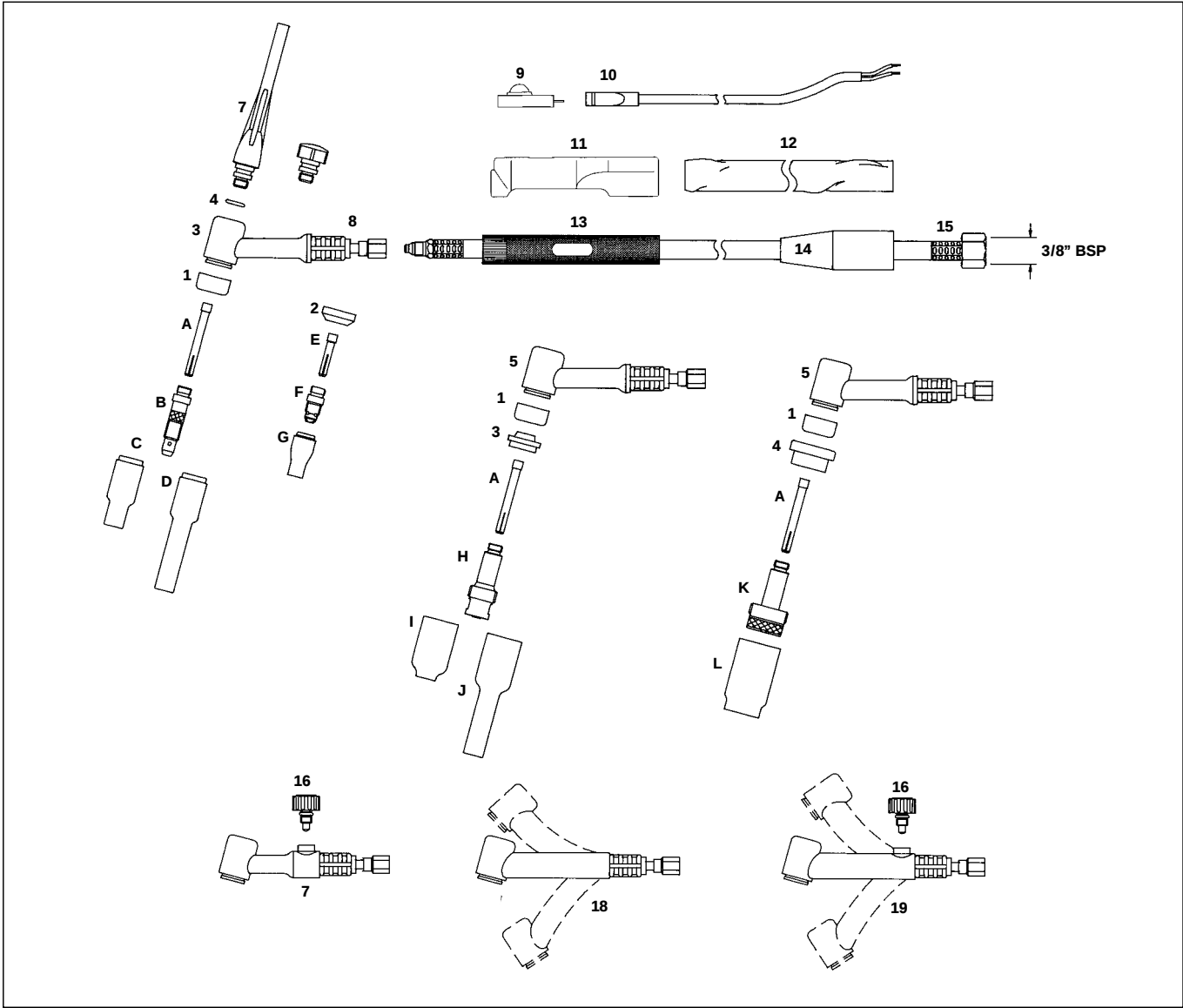

Model		
Description	Part Number	
	12ft	25ft
Tig Welding Torch c/w Vinyl Power Cable	WP17-12	WP17-25
Tig Welding Torch c/w Rubber Power Cable	WP17-12R	WP17-25R
Tig Welding Torch c/w 2 Piece Power Cable	WP17-12-2	WP17-25-2
Tig Welding Torch c/w Vinyl Power Cable, sheath, switch & boot	WP17-12SSW	WP17-25SSW
Tig Welding Torch c/w Rubber Power Cable, sheath, switch & boot	WP17-12RSSW	WP17-25RSSW
Tig Welding Torch c/w 2 Piece Power Cable, sheath, switch & boot	WP17-12-2SSW	WP17-25-2SSW
For torch packages with alternative torch bodies please order with the following prefix		
Model	Description	
WP17V -	Complete Torch packages with Valve	
WP17FX - ie: (WP17FX-12RSSW, WP17 torch with flexi head, 12ft, rubber power cable c/w sheath, switch & boot)	Complete Torch packages with Flexi Head	
WP17VFX -	Complete Torch packages with Flexi Valve	

A Standard Collet	
Part Number	Description
10N21	Standard Collet 0.020 Bore
10N22	Standard Collet 0.040 Bore
10N23	Standard Collet 1/16 Bore
10N23M	Standard Collet 2.0mm Bore
10N24	Standard Collet 3/32 Bore
B Standard Collet Body	
Part Number	Description
10N29	Standard Collet Body.020 Bore
10N30	Standard Collet Body.040 Bore
10N31	Standard Collet Body 1/16 Bore
10N32	Standard Collet Body 3/32 Bore
C Standard Ceramic Cup	
Part Number	Description
10N50	Standard Ceramic Cup 1/4 Bore
10N49	Standard Ceramic Cup 5/16 Bore
10N48	Standard Ceramic Cup 3/8 Bore
10N47	Standard Ceramic Cup 7/16 Bore
10N46	Standard Ceramic Cup 1/2 Bore
10N45	Standard Ceramic Cup 5/8 Bore
10N44	Standard Ceramic Cup 3/4 Bore
D Standard Long Ceramic Cup	
Part Number	Description
10N49L	Long Ceramic Cup 5/16 Bore
10N48L	Long Ceramic Cup 3/8 Bore
10N47L	Long Ceramic Cup 7/16 Bore
E Stubby Series Collet	
Part Number	Description
10N21S	Stubby Collet 0.020 Bore
10N22S	Stubby Collet 0.040 Bore
10N23S	Stubby Collet 1/16 Bore
10N24S	Stubby Collet 3/32 Bore
F Stubby Collet Body	
Part Number	Description
17CB20	Stubby Collet Body 0.020 -1/8 Bore
G Stubby Series Ceramic Cup	
Part Number	Description
13N08	Standard Ceramic Cup 1/4 Bore
13N09	Standard Ceramic Cup 5/16 Bore
13N10	Standard Ceramic Cup 3/8 Bore
13N11	Standard Ceramic Cup 7/16 Bore
13N12	Standard Ceramic Cup 1/2 Bore
13N13	Standard Ceramic Cup 5/8 Bore
H Gas Lens Body	
Part Number	Description
45V29	Gas Lens Body 0.020 Bore
45V24	Gas Lens Body 0.040 Bore
45V25	Gas Lens Body 1/16 Bore
45V26	Gas Lens Body 3/32 Bore

I	Standard Gas Lens Cup	
	Part Number	Description
	54N18	Standard Gas Lens Cup 1/4 Bore
	54N17	Standard Gas Lens Cup 5/16 Bore
	54N16	Standard Gas Lens Cup 3/8 Bore
	54N15	Standard Gas Lens Cup 7/16 Bore
	54N14	Standard Gas Lens Cup 1/2 Bore
	54N19	Standard Gas Lens Cup 1 1/16 Bore
J	Long Gas Lens Cup	
	Part Number	Description
	54N17L	Long Gas Lens Cup 5/16 Bore
	54N16L	Long Gas Lens Cup 3/8 Bore
	54N15L	Long Gas Lens Cup 7/16 Bore
K	Large Diameter Gas Lens Body	
	Part Number	Description
	45V116	Lge Dia Gas Lens Bdy 1/16 Bore
	45V64	Large Dia Gas Lens Body 3/32 Bore
L	Large Diameter Gas Lens Cup	
	Part Number	Description
	57N75	Lge Dia Gas Lens Cup 3/8 Bore
	57N74	Lge Dia Gas Lens Cup 1/2 Bore
	53N88	Lge Dia Gas Lens Cup 5/8 Bore
	53N87	Lge Dia Gas Lens Cup 3/4 Bore
Components		
	Part Number	Description
1	18CG	Cup Gasket
2	18CG20	Cup Gasket
3	54N01	Gas Lens Insulator
4	54N63	Insulator Large Dia G/Lens
5	WP17	Torch Body Angled With Gasket
6	98W18	Back Cap 'O' Ring
7	57Y02	Back Cap Long
8	57Y04	Back Cap Short
9	950	Microswitch Bulbous
NI	950F	Microswitch Flat
10	950-40	Switch & Leads X 4mt
	950-80	Switch & Leads X 8mt
11	RDZ0591	Snap On Boot
NI	607664	Rubber Boot
12	B1537-30	Cable Assembly Cover X 3mt
	B1537-70	Cable Assembly Cover X 7mt
13	105Z55	Handle
14	0315071	Insulation Boot
15	57Y01	Power Cable X 12.5ft Vinyl
	57Y03	Power Cable X 25ft Vinyl
	57Y01R	Power Cable X 12.5ft Rubber
	57Y03R	Power Cable X 25ft Rubber
	57Y01-2	Power Cable X 12.5ft 2 Piece
	57Y03-2	Power Cable X 25ft 2 Piece
16	WP17V	Torch Body Valve
17	VS-2	Valve Stem
18	WP17FX	Torch Body Flexi
19	WP17VFX	Torch Body Flexi-Valve

NI - Not Illustrated