




- Konstantstrømlader for 1-10 NiMH/NiCd-celler
- For 500 mAh-4 Ah batterier (C/10 lading)
- Lineær
- Termosikring i transformator, termisk beskyttelse i regulator, polvendings- og kortslutningssikker
- Plugg-inn enhet
- Lysdiode indikerer lading
- Tilfredsst. medisinsk std (EN 60601)
- Utskiftbare DC plugger
- Constant current charger for 1-10 NiMH/NiCd cells
- For 500 mAh-4 Ah batteries (C/10 charging current)
- Linear
- Thermal fuse in transformer, thermal protection in regulator, protected against reversed polarity and short circuit proof
- Plug-in unit
- LED indicates charging
- Complies w. medical std (EN 60601)
- Exchangeable DC plugs

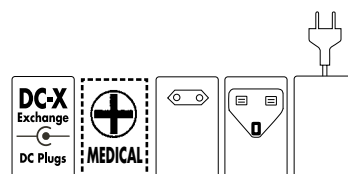

Tekniske data	Technical specifications	
Inngangsspenning:	<i>Input voltage:</i>	230 VAC +6/-10%, 50/60Hz
Ladespenning	<i>Charging voltage</i>	
• Ved tomgang:	• <i>At no load:</i>	Max. 24 V
• Ved 400 mA:	• <i>At 400 mA:</i>	Min. 12 V
Ladestrøm	<i>Charge current</i>	
• Innstillbar:	• <i>Adjustable:</i>	50-400 mA
• < 8,4 V må justeres til:	• <i>< 8,4 V must be limited to:</i>	250 mA
Strømtrekk fra batteri ved frakoblet nett:	<i>Leakage current from battery when mains switched off:</i>	< 0,1 mA
Temperaturområde:	<i>Temperature range:</i>	-20°C - +30°C
Isolasjonsklasse:	<i>Insulation class:</i>	II
Elektrisk sikkerhetsstandard:	<i>Electrical safety standard:</i>	EN 60065, EN 60950
EMC standarder	<i>EMC standards</i>	
• Emisjon:	• <i>Emission:</i>	EN 61000-6-3
• Immunitet:	• <i>Immunity:</i>	EN 61000-6-1
Utgangsterminaler	<i>Output terminals</i>	
• Sek. ledning med/uten plugg:	• <i>Cord with/without plug:</i>	Tilbehør / Accessories
Mål uten plugg (LxBxH):	<i>Dimensions without plug (LxWxH):</i>	100 x 51 x 63 mm
Vekt:	<i>Weight:</i>	450 g
* Kan på bestilling leveres med andre ladestruermer.		
* Can on request be delivered with other charge current.		