

K 50 WP 8 OHM

Art. No. 2915


5 cm (2") full-range speaker with a plastic basket and plastic diaphragm. Broad [frequency response](#) and good voice reproduction. Particularly well suited to outdoor applications and where ambient conditions are generally unfavourable (e.g. high humidity).

Typical applications:


- Monitoring speaker for electronic devices
- Monitoring speaker for outdoor systems

Attributes :

- Plastic: ABS (basket; UL 94: HB); Mylar (diaphragm)
- Functionally at cold according to EN 60068-2-1/EN 50155
- Weather-resistant
- UV-resistant

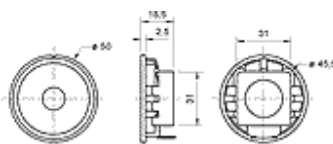


[sketch](#)

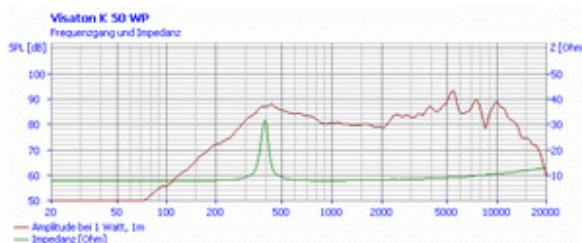

[frequency- and impedance response](#)

IP 65

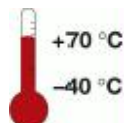

Technical Data:

Rated power	2 W
Maximum power	3 W
Nominal impedance Z	8 Ohm
Frequency response	180–17000 Hz
Mean sound pressure level	86 dB (1 W/1 m)
Resonance frequency fs	300 Hz
Voice coil diameter	10 mm
Cutout diameter	46 mm
Net weight	0,048 kg
Protective system	IP 65
Heat resistance	-40 ... 70 °C

Similar Products

FRS 5 8 OHM	FRWS 5 4 OHM
FRWS 5 8 OHM	FRWS 5 R 8 OHM
FRWS 5 SC 8 OHM	K 50 8 OHM
K 50 SQ 8 OHM	K 50 WP 50 OHM

