

K 64 WP 8 OHM

Art. No. 2918


6,4 cm (2.5") **full-range speaker** with a plastic basket and plastic diaphragm. Broad [frequency response](#) and good voice reproduction. Particularly well suited to outdoor applications and where ambient conditions are generally unfavourable (e.g. high humidity).

Typical applications:


- Monitoring speaker for electronic devices
- Monitoring speaker for outdoor systems

Attributes :

- Weather-resistant
- UV-resistant
- Plastic: ABS (basket; UL 94: HB); Mylar (diaphragm)
- Functionally at cold according to EN 60068-2-1/EN 50155
- Cold storage (-40 °C) according to EN 60068-2-1/EN 50155
- Functionally at damp heat (cyclic) according to EN 60068-2-3/EN 50155
- Functionally at dry heat according to EN 60068-2-2/EN 50155

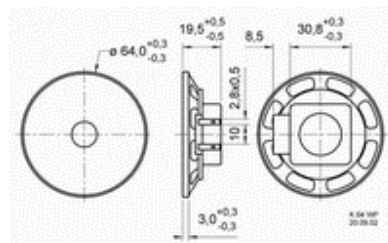

sketch

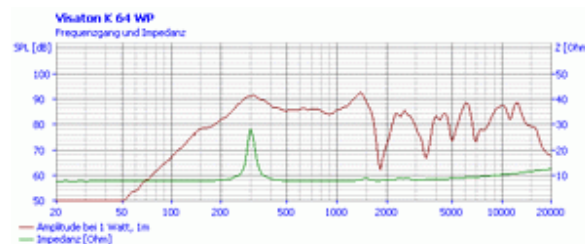

frequency- and impedance response



Technical Data:

Rated power	2 W
Maximum power	3 W
Nominal impedance Z	8 Ohm
Frequency response	200–15000 Hz
Mean sound pressure level	86 dB (1 W/1 m)
Resonance frequency f_s	300 Hz
Magnetic induction	0,7 T
Magnetic flux	45 μ Wb
Height of front pole-plate	2 mm
Voice coil diameter	10 mm
Height of winding	2,5 mm
Cutout diameter	60 mm
Net weight	0,05 kg
Protective system	IP 65
Heat resistance	-25 ... 60 °C

Similar Products

FR 7 4 OHM	FRS 7 4 OHM
FRS 7 8 OHM	FRS 7 S 8 OHM
K 64 WP 50 OHM	K 64 WPT 8 OHM

