

## FX 10 4 OHM

**Art. No. 4692**

**10 cm (4") 2-way coaxial loudspeaker** with standard basket. Integrated [crossover \(capacitor\)](#) for the tweeter. Straightforward installation in vehicles with cutouts for 10 cm speakers. Waterproof PP-cone.

**Typical applications:**



- Vehicles
- Mobile homes

**Attributes:**


- Waterproof [cone](#)
- Metal basket
- Coaxial speaker

**Used in / Accessories:**

- [GRILLE 10 ES](#)
- [GRILLE 10 R/134](#)
- [GRILLE 10 RS](#)
- [GRILLE 10 PL](#)

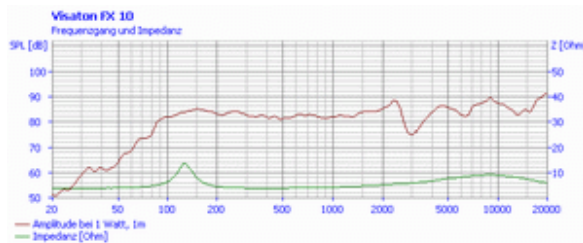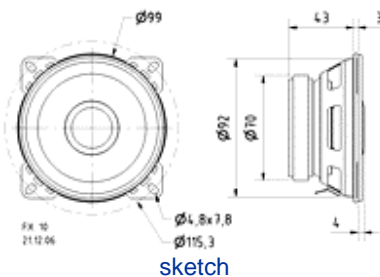


[frequency- and impedance response](#)

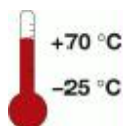


Technical Data:	
Rated power	40 W
Maximum power	70 W
Nominal impedance Z	4 Ohm
Frequency response	70–22000 Hz
Mean sound pressure level	84 dB (1 W/1 m)
Resonance frequency fs	110 Hz
Height of front pole-plate	3 mm
Voice coil diameter	25 mm
Height of winding	6 mm
Cutout diameter	93 mm
Net weight	0,4 kg
Heat resistance	-25 ... 70 °C


Similar Products	
<a href="#">DX 10 4 OHM</a>	<a href="#">DX 13 4 OHM</a>
<a href="#">DX 4x6 P 4 OHM</a>	<a href="#">FX 13 4 OHM</a>
<a href="#">PX 10 4 OHM</a>	<a href="#">PX 13 4 OHM</a>

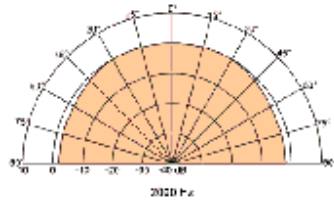

[radiation pattern 2000 Hz](#)

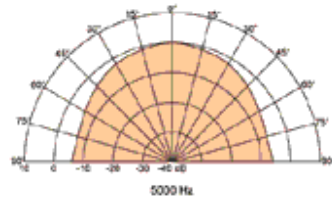

[radiation pattern 5000 Hz](#)

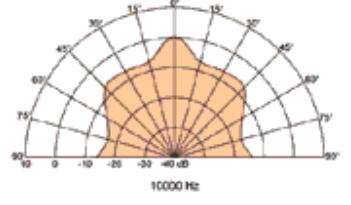

[radiation pattern 10000 Hz](#)