


Type: **U-PKZ0(415V50HZ)**  
 Article No.: **073139**



### Ordering information

Actuating voltage		415 V 50Hz
For use with		PKZM0 PKZM4 auf Anfrage PKZM0-T PKM0

### Contact sequence

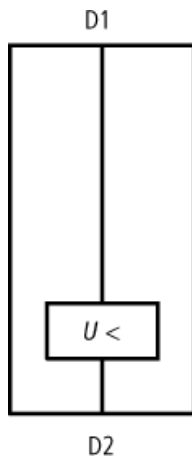


### General

Terminal capacities		
Solid or flexible conductor with ferrule	mm <sup>2</sup>	1 × (0.75 – 2.5) 2 × (0.75 – 2.5)
Solid or stranded	AWG	

			1 × (18 – 14)
			2 × (18 – 14)
<b>Main conducting paths</b>			
Rated operating voltage	$U_e$	V AC	42 – 480
Rated operating voltage	$U_e$	V DC	24 – 250
<b>Power consumption</b>			
AC			
Pick-up AC	Pick-up	VA	5
Sealing AC	Sealing	VA	3
<b>Pick-up-/drop-out voltage</b>			
Pick-up voltage			
Pick-up voltage, min.		$\times U_s$	0,85
Pick-up voltage, max.		$\times U_s$	1,1
Drop-out voltage			
Drop-out voltage, min.		$\times U_s$	0,7
Drop-out voltage, max.		$\times U_s$	0,35
<b>Dimensions</b>			

## Dimensions

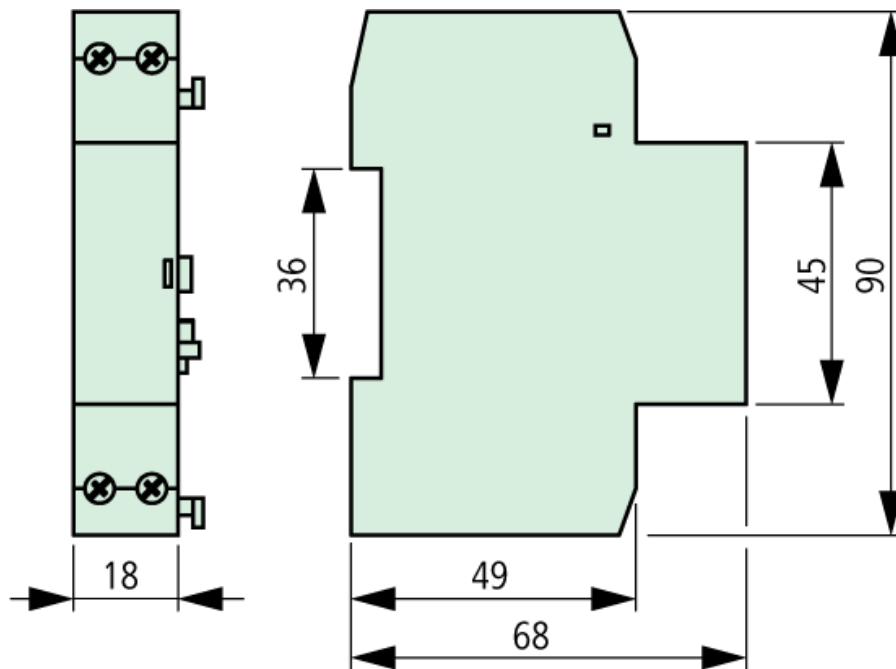

Moeller GmbH, Hein-Moeller-Str. 7-11, D-53115 Bonn  
 E-Mail: [catalog@moeller.net](mailto:catalog@moeller.net), Internet: [www.moeller.net](http://www.moeller.net), <http://catalog.moeller.net>  
 Copyright 2006 by Moeller GmbH. Subject to modifications. HPL-C2006GB-INT V2.3