



## LK2125100K-T

Size	2012(0805)	Inductance	10 $\mu$ H -10 to 10%
Inductance Tolerance	-10 to 10%	Inductance Measuring Frequency	2MHz
Rated Current	15mA	Max. of DC. Resistance	0.8 $\Omega$
Avg. of DC. Resistance	--	Q min.	50
Q Frequency	2MHz	Self-resonant Frequency	24MHz
Min. of Operating Temp.	-40℃	Max. of Operating Temp.	85℃
Length	2mm+0.3:-0.1mm	Width	1.25mm $\pm$ 0.2mm
Thickness	1.25mm $\pm$ 0.2mm		

### Q-Characteristics

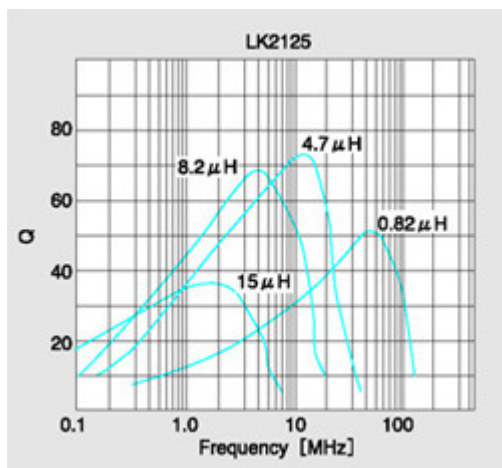

### DC Bias Characteristics

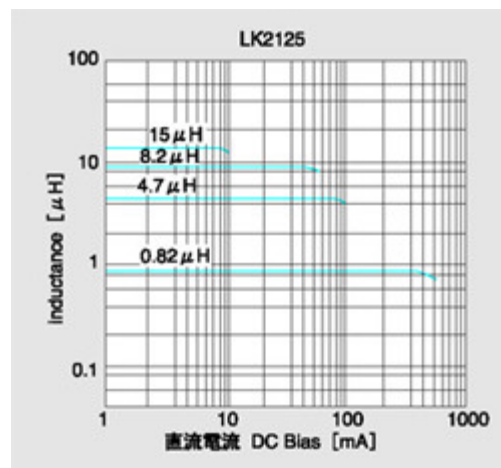

### Temperature Characteristics

