


- HellermannTyton cable ties - customer specified worldwide
- Injection moulded in high grade nylon 6.6
- Superior quality, design and manufacture
- Quick, simple fixing by hand or with HellermannTyton tensioning tools
- Products approved to U.S. Military specification 23190 drawing MS3367

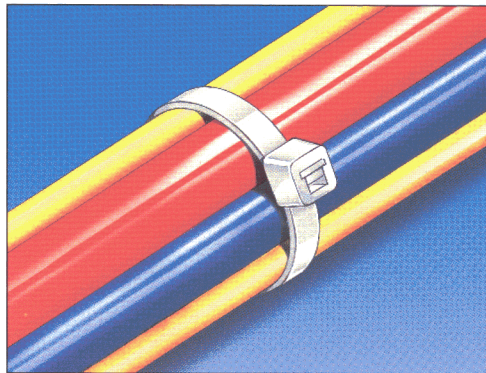

### Military Specification Ties

Material - High grade Nylon 6.6



Product Reference	Overall Length mm	Strap Width mm	Minimum Tensile Strength		Maximum Cable Diameter mm	Recommended Tensioning Tool
			lbs	N		
T18S	80	2.3	18	80	16	MK3/MK20/MK7
T18R	100	2.5	18	80	22	MK3/MK20/MK7
T18I	144	2.5	18	80	33	MK3/MK20/MK7
T18L	200	2.5	18	80	53	MK3/MK20/MK7
T25R	100	2.5	25	113	16	MK3/MK20/MK7
T25L	250	2.5	25	113	65	MK3/MK20/MK7
T25LL	330	2.5	25	113	95	MK3/MK20/MK7



T30R	150	3.6	30	133	35	MK3/MK20/MK7
T30L	200	3.6	30	133	50	MK3/MK20/MK7
T30LL	300	3.6	30	133	75	MK3/MK20/MK7
T30XL	368	3.6	30	133	100	MK3/MK20/MK7




T40R	180	4.0	40	178	42	MK3/MK20/MK7
------	-----	-----	----	-----	----	--------------



# Cable Ties & Bundling Systems

## Military Specification Ties


- Lightweight, high strength fixings
- One piece, all plastic construction
- ISO 9002 approved
- Range of different materials available for high specification environments

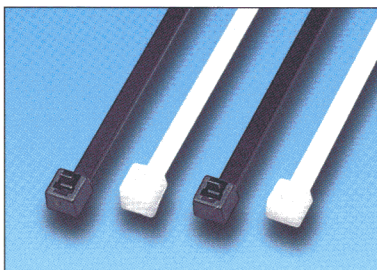

### Military Specification Ties

Material - High grade Nylon 6.6

 Product Reference	Overall Length mm	Strap Width mm	Minimum Tensile Strength		Maximum Cable Diameter mm	Recommended Tensioning Tool
			lbs	N		
T50S	150	4.8	50	222	36	MK3/MK20/MK7
T50R	200	4.8	50	222	50	MK3/MK20/MK7
T50M	250	4.8	50	222	65	MK3/MK20/MK7
T50I	300	4.8	50	222	81	MK3/MK20/MK7
T50L	385	4.8	50	222	107	MK3/MK20/MK7
T50LL	445	4.8	50	222	132	MK3/MK20/MK7



T80R	205	4.8	80	356	50	MK3/MK20/MK7/MK9
T80I	300	4.8	80	356	81	MK3/MK20/MK7/MK9
T80L	390	4.8	80	356	108	MK3/MK20/MK7/MK9



T120S	225	7.6	120	536	51	MK6/MK21/MK9
T120I	300	7.6	120	536	75	MK6/MK21/MK9
T120R	385	7.6	120	536	107	MK6/MK21/MK9
T120M	465	7.6	120	536	130	MK6/MK21/MK9
T120XM	610	7.6	120	536	170	MK6/MK21/MK9
T120L	760	7.6	120	536	220	MK6/MK21/MK9

